

# Female wing knob

Stock


GGB

Technopolymer with brass insert

- Female wing knob with tapped hole (blind or fully threaded)
- For manual tightening
- Material:  
Matt black polyamide with brass insert

## Info.

- Not sold individually, please contact us for details

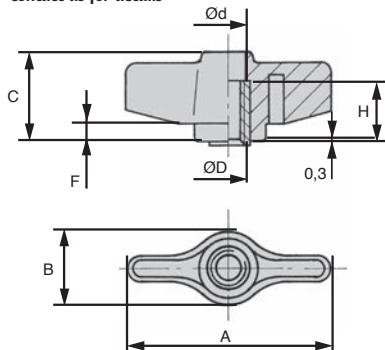

with brass insert

## DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	B	C	ØD	Ød	H	F	Stock*	Price each 1 to 9
<b>Knob with blind thread</b>									
GGB34-M6	34	14	18	M6	-	9	4	✓	1,88 €
GGB34-M8	34	14	18	M8	-	9	4	✓	1,88 €
GGB40-M6	40	15	19	M6	-	9	4	✓	1,98 €
GGB40-M8	40	15	19	M8	-	9	4	✓	1,98 €
GGB48-M6	48	17	20	M6	-	13	4	-	2,06 €
GGB48-M8	48	17	20	M8	-	13	4	✓	2,06 €
<b>Knob, fully threaded</b>									
GGB34-M6/FP	34	14	18	M6	7	15	4	✓	2,06 €
GGB40-M6/FP	40	15	19	M6	9	15	4	✓	2,11 €
GGB40-M8/FP	40	15	19	M8	9	15	4	✓	2,11 €
GGB48-M6/FP	48	17	20	M6	9	15	4	✓	2,21 €
GGB48-M8/FP	48	17	20	M8	9	15	4	✓	2,21 €

\*Depending on availability - Dimensions in mm

## Our other products



PTA50ssEB

Articulated foot with sheet metal base Ø50, Articulated foot



SHTP

Drylin® Linear table, Economy range



MHWC

Double-disc flexible coupling, Double disk



PFC

Fixed rubber levelling foot, Levelling support for small parts



PRF\_ART

Articulated bracket for use with aluminium profile, Standard



PDD

Spring plunger, With sensor adaptor



UGPL

Actuator guide kit, Long bearing



MRAeco

Low cost quick link, Steel



KKSS

Rounded end feather key, Stainless steel



GPLbr

Brush, brass



ACLEPP

Right angled bracket for aluminium profile, 4 holes



VBFP

Small 6 lobe threaded handle - female, Duroplast - Stainless steel

## Complementary products



GGB

Female wing knob, Fully threaded



GGP

Male wing knob, Technopolymer with stainless steel spindle