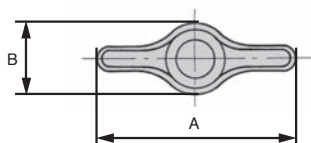
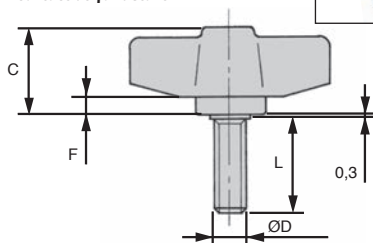


- Male wing knob
- For manual tightening
- Material:
Matt black polyamide
Threaded shaft: zinc plated steel or stainless steel

Info.

- Not sold individually, please contact us for details

shaft zinc
plated steel or
stainless steel

**DISCOUNTS**

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	B	C	ØD	L	F	Stock*	Price each 1 to 9
Steel								
GGP34-M6-25	34	14	18	M6	25	4	✓	2,06 €
GGP34-M8-25	34	14	18	M8	25	4	✓	2,21 €
GGP40-M8-25	40	15	19	M8	25	4	✓	2,41 €
GGP48-M8-25	48	17	20	M8	25	4	✓	2,83 €
GGP48-M8-40	48	17	20	M8	40	4	✓	2,88 €
Stainless steel								
GGP34-M6-20/SS	34	14	18	M6	20	4	✓	4,46 €
GGP34-M6-30/SS	34	14	18	M6	30	4	-	4,69 €

*Depending on availability - Dimensions in mm

Our other products



PRF-SCREEN-5

Screen support,
Support with 5 axes of
rotation



ZG3

Plastic spur gear,
Machined plastic
(delrin)



AT5M AT10M

AT type timing belt
per metre, AT5 Steel
cored polyurethane



BPM

Slotted spring plunger
with ball tip, Steel



 
RT61ss

Self-centering locking
Assembly,
Medium/low torque



SHA_PT

Handwheel with
handle, Polyamide



PF70

Worm and wheel gear
reducer, up to 164
Nm



LWL

Linear ball slide -
Stainless steel balls,
Rail - from 514 N to
1670...



DEP

Tools Hygienic Usit®
and Hygienic



PAMF100EB

Articulated foot with
sheet metal base



BFDdII

Locking pin for
bushes, Nickel-plated



NDS20

Double cross clamp,
Parallel

Complementary products



GGB

Female wing knob,
With blind thread



GGB

Female wing knob,
Fully threaded