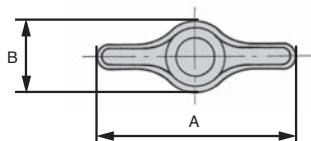
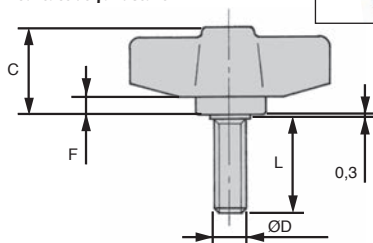


- Male wing knob
- For manual tightening
- Material:
Matt black polyamide
Threaded shaft: zinc plated steel or stainless steel

Info.

- Not sold individually, please contact us for details

shaft zinc
plated steel or
stainless steel


**DISCOUNTS**

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	A	B	C	ØD	L	F	Stock*	Price each 1 to 9
Steel								
GGP34-M6-25	34	14	18	M6	25	4	✓	2,06 €
GGP34-M8-25	34	14	18	M8	25	4	✓	2,21 €
GGP40-M8-25	40	15	19	M8	25	4	✓	2,41 €
GGP48-M8-25	48	17	20	M8	25	4	✓	2,83 €
GGP48-M8-40	48	17	20	M8	40	4	✓	2,88 €
Stainless steel								
GGP34-M6-20/SS	34	14	18	M6	20	4	✓	4,46 €
GGP34-M6-30/SS	34	14	18	M6	30	4	-	4,69 €

*Depending on availability - Dimensions in mm

Our other products

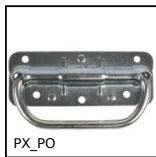

PX_PO
Carrying handle, back-plated



PGM86-M5
Pull handle, Thermoplastic



M1
Worm and wheel set, Non hardened steel



SSE
Stainless steel spherical bearing, Stainless steel / PTFE



AT5courroie
AT type timing belt, AT5 Steel cored polyurethane



DOMI80
Domino 80 adjustable slide, Slide DOMILINE 80 with counter and handw...



CHA35
Hinge for aluminium profile, Hinge



CHA35
Hinge for aluminium profile, Hinge




BIM
Indexing plunger mini, miniature



T5M_T10M
T type timing belt per metre, T10 Steel cored polyurethane



 BAC110
Swivel storage bin, Storage bin



RPP
Connecting plate for RPP type timing belts, RPP8

Complementary products



GGB
Female wing knob, With blind thread



GGB
Female wing knob, Fully threaded