

Small 6 lobe female handle

Stock

GLB Technopolymer, with brass insert

- Small 6 lobe handle with a female tapped insert (blind or fully threaded)

- Material :


Matt black polyamide with brass or stainless steel insert

with brass or stainless steel insert



Info.

- Not sold individually, please contact us for details

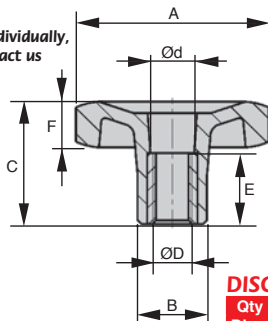


DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number		A	B	C	F	ØD	E	Ød	Stock*	Price each 1 to 9	
Steel	S/steel								Steel	Steel	S/steel
Handle, blind thread											
GLB30-M6	GLB30-M6/SS	30	14	24	15	M6	13	-	✓	2,41 €	6,07 €
GLB30-M8	-	30	14	24	15	M8	13	-	✓	2,55 €	-
GLB40-M6	GLB40-M6/SS	40	16	28	18	M6	13	-	✓	2,83 €	6,86 €
GLB40-M8	GLB40-M8/SS	40	16	28	18	M8	13	-	✓	2,83 €	6,90 €
GLB50-M8	GLB50-M8/SS	50	18	32	20	M8	15	-	✓	3,32 €	8,70 €
GLB50-M10	GLB50-M10/SS	50	18	32	20	M10	16	-	✓	3,56 €	8,70 €
GLB60-M12	GLB60-M12/SS	60	20	36	22	M12	18	-	✓	4,79 €	14,06 €
GLB70-M12	-	70	23	40	24	M12	18	-	✓	5,99 €	-
GLB70-M14	-	70	23	40	24	M14	20	-	✓	7,47 €	-
GLB70-M16	-	70	23	40	24	M16	20	-	✓	7,99 €	-
Handle fully threaded											
GLB30-M6/FP	GLB30-M6/FP/SS	30	14	24	15	M6	11	8	✓	2,98 €	10,27 €
GLB30-M8/FP	-	30	14	24	15	M8	11	10	✓	3,27 €	-
GLB40-M6/FP	GLB40-M6/FP/SS	40	16	28	18	M6	15	7	✓	3,65 €	11,42 €
GLB40-M8/FP	GLB40-M8/FP/SS	40	16	28	18	M8	15	11	✓	3,90 €	12,16 €
GLB50-M8/FP	GLB50-M8/FP/SS	50	18	32	20	M8	18	11	✓	4,70 €	13,33 €
GLB50-M10/FP	GLB50-M10/FP/SS	50	18	32	20	M10	18	11	✓	4,83 €	14,06 €
GLB60-M12/FP	-	60	20	36	22	M12	25	13	✓	6,46 €	-
GLB70-M12/FP	-	70	23	40	24	M12	25	14	✓	8,04 €	-
GLB70-M14/FP	-	70	23	40	24	M14	25	15	✓	9,82 €	-
GLB70-M16/FP	-	70	23	40	24	M16	25	17	✓	11,43 €	-

*Depending on availability - Dimensions in mm

 
Our other products



B
Steel bevel gear, 1:1



 CHA60
Rectangular hinge,
drilled or countersunk,
Rectangular, drilled or
C...



KITdog
24V DC motorisation
kit, Worm and wheel



CHASb63
Hinge without pin,
Polymer pin hinge



 
CHAR5050_Z
Spring hinge, screwed



PW_PWG2
Wheel - precision
range, Bronze



HTD8M_50
HTD Heavy duty
timing pulley, HTD8
Cast



KS
Keysteel, Stainless
steel - Keystock



PTA80
Articulated levelling
foot, pressed base
Ø80, Ø 80



AT5courroie
AT type timing belt,
AT5 Steel cored
polyurethane



CHB
Double output shaft,
For CHB gearbox



GTCS5
Belt tensioner, For use
in hostile
environments

Complementary products



GLB
Small 6 lobe threaded
handle - female,
Technopolymer -
Brass



GLB
Small 6 lobe female
handle,
Technopolymer -
Stainless steel



VTLF
3 lobed handle,
Polyamide - Brass



VTLF
3 lobed handle,
Polyamide - Brass