

# Small 6 lobe threaded handle

Stock

GLB Technopolymer with brass insert

Brass or stainless steel insert

- Small 6 lobe handle with a tapped insert (blind or fully threaded)


- Material :

Matt black polyamide with brass or stainless steel insert



## Info.

- Not sold individually, please contact us for details

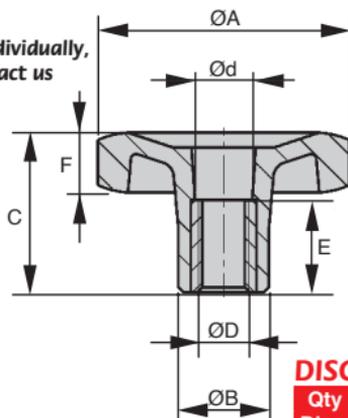

## DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request


Part number		ØA	ØB	C	F	ØD	E	Ød	Stock*	Price each 1 to 9	
Steel	S/steel								Steel	Steel	S/steel
<b>Handle, blind thread</b>											
GLB30-M6	GLB30-M6/SS	30	14	24	15	M6	13	-	✓	2,88 €	7,28 €
GLB30-M8	-	30	14	24	15	M8	13	-	✓	3,03 €	-
GLB40-M6	GLB40-M6/SS	40	16	28	18	M6	13	-	✓	3,38 €	8,24 €
GLB40-M8	GLB40-M8/SS	40	16	28	18	M8	13	-	✓	3,38 €	8,28 €
GLB50-M8	GLB50-M8/SS	50	18	32	20	M8	15	-	✓	3,98 €	10,44 €
GLB50-M10	GLB50-M10/SS	50	18	32	20	M10	16	-	✓	4,26 €	10,44 €
GLB60-M12	GLB60-M12/SS	60	20	36	22	M12	18	-	✓	5,75 €	16,92 €
GLB70-M12	-	70	23	40	24	M12	18	-	✓	7,18 €	-
GLB70-M14	-	70	23	40	24	M14	20	-	✓	8,98 €	-
GLB70-M16	-	70	23	40	24	M16	20	-	✓	9,60 €	-
<b>Handle fully threaded</b>											
GLB30-M6/FP	GLB30-M6/FP/SS	30	14	24	15	M6	11	8	✓	3,57 €	12,36 €
GLB30-M8/FP	-	30	14	24	15	M8	11	10	✓	3,90 €	-
GLB40-M6/FP	GLB40-M6/FP/SS	40	16	28	18	M6	15	7	✓	4,38 €	13,74 €
GLB40-M8/FP	GLB40-M8/FP/SS	40	16	28	18	M8	15	11	✓	4,66 €	14,61 €
GLB50-M8/FP	GLB50-M8/FP/SS	50	18	32	20	M8	18	11	✓	5,63 €	16,04 €
GLB50-M10/FP	GLB50-M10/FP/SS	50	18	32	20	M10	18	11	✓	5,81 €	16,92 €
GLB60-M12/FP	-	60	20	36	22	M12	25	13	✓	7,75 €	-
GLB70-M12/FP	-	70	23	40	24	M12	25	14	✓	9,68 €	-
GLB70-M14/FP	-	70	23	40	24	M14	25	15	✓	11,80 €	-
GLB70-M16/FP	-	70	23	40	24	M16	25	17	✓	13,75 €	-

\*Subject to availability - Dimensions in mm

- Small 6 lobe male handle with steel spindle
- Material :  
Matt black polyamide  
Spindle: zinc plated steel or stainless steel

### Option

- Stainless steel or polyamide coloured (min quantity applies) insert on quantities

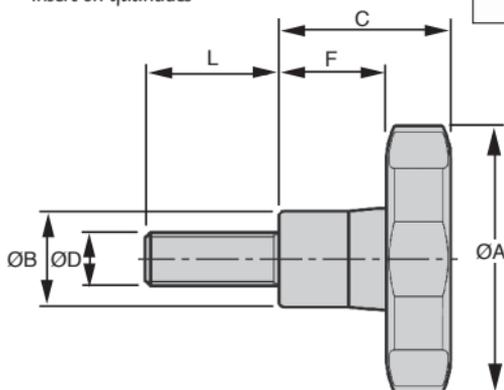

### DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number		ØA	ØB	C	F	ØD	L	Stock*	Price each 1 to 9	
Steel	Stainless steel								Steel	Stainless steel
GLP30-M6-20	GLP30-M6-20/SS	30	14	24	15	M6	20	✓	2,65 €	6,40 €
GLP30-M6-30	GLP30-M6-30/SS	30	14	24	15	M6	30	✓	2,88 €	6,55 €
GLP30-M8-20	-	30	14	24	15	M8	20	✓	2,88 €	-
GLP30-M8-30	-	30	14	24	15	M8	30	✓	2,93 €	-
GLP40-M8-20	GLP40-M8-20/SS	40	16	28	18	M8	20	✓	3,20 €	7,58 €
GLP40-M8-30	GLP40-M8-30/SS	40	16	28	18	M8	30	✓	3,28 €	8,02 €
GLP40-M8-40	-	40	16	28	18	M8	40	✓	3,38 €	-
GLP50-M10-20	-	50	18	32	20	M10	20	✓	4,47 €	-
GLP50-M10-30	GLP50-M10-30/SS	50	18	32	20	M10	30	✓	4,60 €	11,97 €
GLP50-M10-40	GLP50-M10-40/SS	50	18	32	20	M10	40	✓	4,72 €	12,14 €
GLP60-M12-30	GLP60-M12-30/SS	60	20	36	22	M12	30	✓	7,69 €	14,61 €
GLP60-M12-50	GLP60-M12-50/SS	60	20	36	22	M12	50	✓	8,38 €	16,92 €
GLP70-M12-30	-	70	23	40	24	M12	30	-	8,38 €	-
GLP70-M12-50	-	70	23	40	24	M12	50	✓	8,98 €	-

\*Subject to availability - Dimensions in mm