


- Small aluminium slide
- Extends fully
- With end stop



Miniature
format

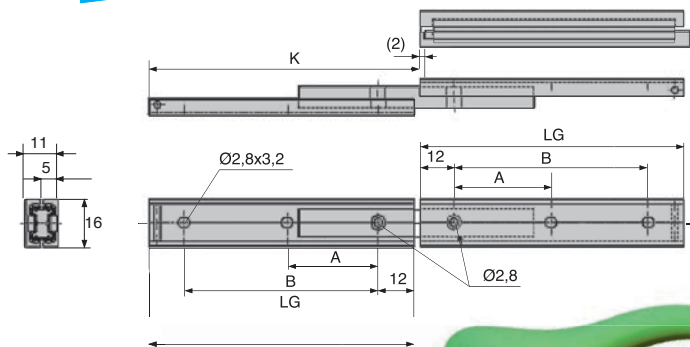

DISCOUNTS

Qty	1+	9+	20+	40+
Disc.	List	-5%	-10%	On request

Part number	Stroke K	LG	A	B	Nominal load	Weight (g)	Price each 1 to 8
GLT16-80	77	80	-	56	20	31,5	34,52 €
GLT16-100	117	100	38	76	29	36,0	36,61 €
GLT16-150	151	150	63	126	39	54,5	47,83 €

Our other products



Moulded plastic bevel gear (nylon), 1.5:1




Drylin® W bearing block, Slide




Multifunction display, Articulated support



Reducing sleeve for OP indicators, Reduction socket

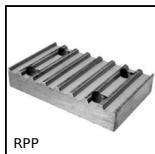

Connecting plate for RPP type timing belts, RPP8

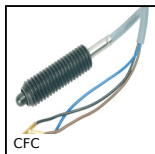

Spring loaded position switch, Electric contact



Steel leadscrew, Medium carbon steel - 1 thread



Moulded plastic spur gear, Moulded plastic (nylon)



Manual leadscrew table with opposing threads, 5kg



Stainless/Polymer pillow block bearing, Polymer and stainless steel



Elastic ringed latch, Hooks into a slot



Skive hobbled spur gears - precision range, Case hardened steel 20NCD2

Complementary products