

Partial extension, suitable for
loads up to 35kg

GLT2


- **Partially extending telescopic slide**
- Travel is less than the length of the slide
- Slides can extend to either side
- Materials:
 - Slides: hot dipped galvanised steel
 - Plastic ball cages
 - Hardened steel balls

Advantage




- Cost effective solution for drawers or similar elements with a low coefficient of friction

Info.

- The dynamic load figures given are the maximum value for a pair of vertically mounted slides over the full length of travel
- Values are given for a maximum of 100,000 operating cycles
- When mounted horizontally, the maximum load figure will be 50-60% less
- **Sold individually**

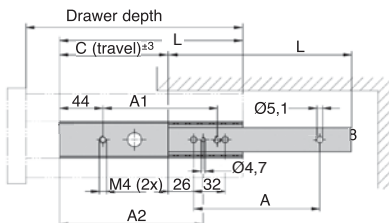

New range

 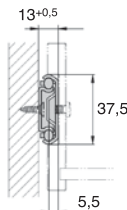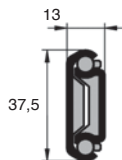

DISCOUNTS

Qty	1+	9+	20+	40+
Disc	List	-5%	-10%	On request

Part number	A	A1	A2	L	Travel C	Drawer depth	Load capacity per pair (vertical)	Load capacity per pair (horizontal)	Weight per pair (kg)	Price each 1 to 8
GLT2-37-154	192	166	202	242	154	242 - 380	35	10	0,59	8,40 €
GLT2-37-317	256	241	277	317	229	317 - 530	35	10	0,78	9,19 €
GLT2-37-398	352	322	358	398	298	398 - 680	35	10	0,96	10,29 €
GLT2-37-473	416	397	433	473	373	473 - 780	35	10	1,14	11,23 €

Dimensions in mm

Our other products



Timing belt per metre,
T5 Steel cored
polyurethane



Panel accessories,
Door seal - Ø 2mm



Drip feeder, For
lubrication or dosing



Bevel gear - Steel
C43, 3:1



Pivoting wheel with
double brake, Steel -
grey rubber



Index bolt, miniature -
Stainless steel



Swivelling base clevis,
Steel long



Small 6 lobe threaded
handle,
Technopolymer -
Stainless steel



Timing belt per metre,
AT10 Steel cored
polyurethane



Clamp, Vertical Lever
Clamp - steel



Detector support,
Sensor holder



Linear motorised
operator, 1 ampere

Complementary products



Telescopic slide rule,
Partial extension



Telescopic slide rule,
Full extension,
removable