

Flat profile - Round guide



GMC
GMCss

For bottling and
packaging applications

- Guide profile for conveying products

- Materials:

Guide: DESLIDUR polyethylene (UHMW1000)

Support: steel or stainless steel

- Green

Accessories


- Fixing clips **GMC-BR**

- Supports **SDG**

Suitable for guiding
many different
products



Typical application

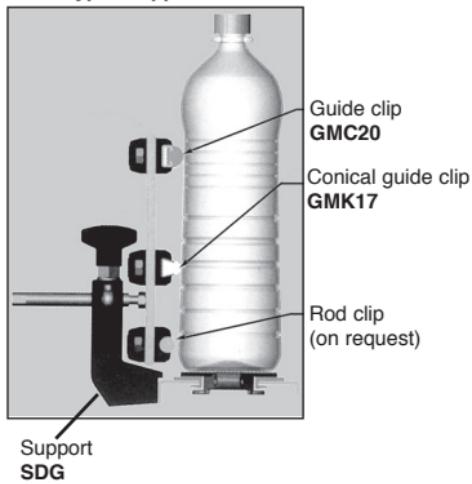

DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Length (mm)	Support material	Weight (kg/m)	Stock*	Price each
GMC20-3000	3000	Steel	0,70	✓	50,59 €
GMC20-3000/SS	3000	Stainless steel	0,70	✓	78,70 €

*Depending on availability - Dimensions in mm

Our other products



UCFL_SS

Stainless steel flanged bearing, Stainless steel



H2

Crossed helical gear crossed axis at 90°, Steel 20NCD2



CHM63

Worm and wheel gear reducer, up to 196 Nm



BH01

Single housed bearing, Bearing fitted with adhesive



LWH

High rigidity linear slide, Rail - from 9320 N to 71300 N



RPCpl

Swivel castor with double brake, Steel - Polyamide



SLHHlok

Horizontal toggle clamp, Horizontal toggle clamp / horizontal foot



VDSCB

Sliding lock adjustment system, Blocking wedge for sliding lock for ...



CHMX_CHMDX

Shaft for worm and wheel reducer CHMR



BOX-TOR-TOOL

Box set of tool for Nitrile O-rings,



BPVMss

Stainless steel miniature ball transfer



LF

Precision locknut, Precision locknut

Complementary products



GMC_GMK_BR

Guiding profile clamp, Flat or rounded



SDG

Adjustable guide support bracket, Plastic



GDR880

Straight track for slat top chain, Ranges 880 and 881



STL

Guidance brush - Rail, Rail