

# Flat profile - Round guide



**GMC**  
**GMCss**

For bottling and  
packaging applications

- **Guide profile for conveying products**
- **Materials:**
  - Guide: DESLIDUR polyethylene (UHMW1000)
  - Support: steel or stainless steel
- Green

## Accessories



- Fixing clips **GMC-BR**
- Supports **SDG**

Suitable for guiding  
many different  
products



steel or  
stainless steel  
support

## Typical application

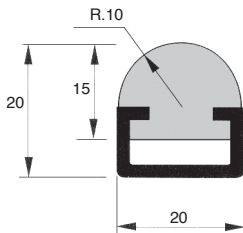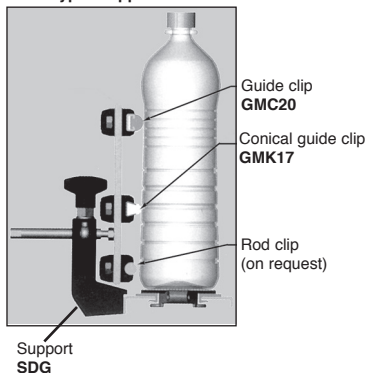

## DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Length (mm)	Support material	Weight (kg/m)	Stock*	Price each
GMC20-3000	3000	Steel	0,70	✓	50,59 €
GMC20-3000/SS	3000	Stainless steel	0,70	✓	78,70 €

\*Depending on availability - Dimensions in mm

**HPC**

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



EKG5  
Backlash free  
coupling Gerwah®,  
from 0.5 to 35Nm



ACLCHAR  
Hinge for aluminium  
profile, With  
elongated holes



PCS50K  
Chain sprocket with  
hardened teeth,  
12.7mm (DIN08B-1)



KB\_OP  
Open precision linear  
bearing, Precision -  
steel



BPPL  
Mini plain bearing ball  
transfer unit, For  
countersinking



ATZYSS  
Stainless steel diaboloid  
shaped elastomeric mount,  
Stainless steel



DKONSL  
Silicone conical elastomeric  
buffer, Male mounting



NT63  
Spur gear coaxial  
gearbox, from 8 to 20  
Nm - Inline



SBF  
Sealed flange bearing  
unit for Food Industry,  
cover



MACss  
Stainless steel  
carabiner, Stainless  
steel



PCS37SS  
Chain sprocket -  
Stainless steel, 9.525  
(DIN 06B-1)



NKIA  
Combined bearing  
with inner ring, Axial  
load in one direction

## Complementary products



GMC\_GMK\_BR  
Guiding profile clamp,  
Flat or rounded



SDG  
Adjustable guide  
support bracket,  
Plastic



GDR880  
Straight track for slat  
top chain, Ranges 880  
and 881



STL  
Guidance brush - Rail,  
Rail