

Flat profile - Round guide



GMC
GMCss

For bottling and
packaging applications

- Guide profile for conveying products
- Materials:
 - Guide: DESLIDUR polyethylene (UHMW1000)
 - Support: steel or stainless steel
- Green



Accessories

- Fixing clips **GMC-BR**
- Supports **SDG**

Suitable for guiding
many different
products



Typical application

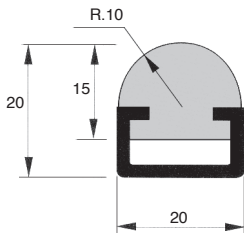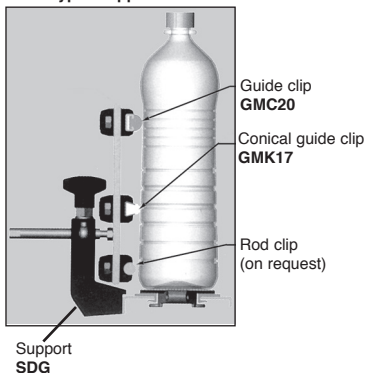

DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Length (mm)	Support material	Weight (kg/m)	Stock*	Price each
GMC20-3000	3000	Steel	0,70	✓	50,59 €
GMC20-3000/SS	3000	Stainless steel	0,70	✓	78,70 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



BSPM

Miniature ballscrew,
Nut+rolled ballscrew



CHA138

Screwed hinge with
threaded insert, 138
degrees



UGCG

Actuator guide kit,
Long housing



PM2

Worm and wheel set,
Hardened steel



DPAR_DKON

Conical elasto buffer,
Steel



ZHG5

Plastic spur gear,
Machined plastic
(delrin)




BCTH

Mushroom headed
button Hygienic
Usit®, With female
thread and high ...



HLUT

Spoked handwheel
with handle,
Aluminium

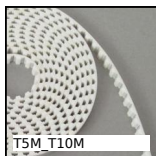

T5M_T10M

T type timing belt per
metre, T10 Steel



RCX-6

Spherical tilt washer -
DIN6319, concave



D-PAR_SS

Stainless steel elasto
mount, stainless steel



PTMR

Telescopic furniture
foot, threaded stud

Complementary products



GMC_GMK_BR

Guiding profile clamp,
Flat or rounded



SDG

Adjustable guide
support bracket,
Plastic



GDR880

Straight track for slat
top chain, Ranges 880
and 881



STL

Guidance brush - Rail,
Rail