

Flat profile - Round guide



GMC
GMCss

For bottling and
packaging applications

- Guide profile for conveying products
- Materials:
 - Guide: DESLIDUR polyethylene (UHMW1000)
 - Support: steel or stainless steel
- Green



Accessories

- Fixing clips **GMC-BR**
- Supports **SDG**

Suitable for guiding
many different
products



Typical application

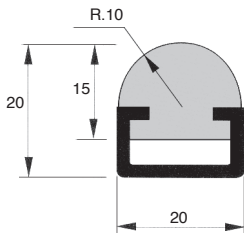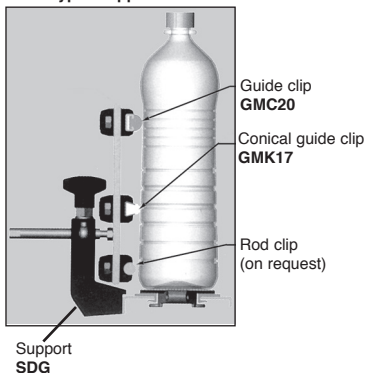

DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Length (mm)	Support material	Weight (kg/m)	Stock*	Price each
GMC20-3000	3000	Steel	0,70	✓	50,59 €
GMC20-3000/SS	3000	Stainless steel	0,70	✓	78,70 €

*Depending on availability - Dimensions in mm

Our other products



PM2

Worm and wheel set,
Non hardened steel



CQA20

Adjustment slide-
system miniature, 20



MFB_MHB

Moulded plastic bevel
gear (nylon), 4:1



RVM14

Manual worm and
wheel gearbox,
Worm/wheel



DOMI50

Connecting kits, XY
linking kit



BLHM60

Right angled gearbox,
double output shafts,
up to 70 Nm



BCA

Steel splined collar,
Steel




NT63

Spur gear coaxial
gearbox, from 8 to 20
Nm - In-line



CHASb63

 Hinge without pin,
Polymer pin hinge



LWH

High rigidity linear
slide, Chariot - from



PCS50K

Chain sprocket with
hardened teeth,



BMM

Knurled knob - male,
Knurled

Complementary products



GMC_GMK_BR

Guiding profile clamp,
Flat or rounded



SDG

Adjustable guide
support bracket,
Plastic



GDR880

Straight track for slat
top chain, Ranges 880
and 881



STL

Guidance brush - Rail,
Rail