



Guiding profile clamp




Plastic

GMCBR
GMKBR

- Single clip for GMC and GMK guides
- Materials:
Clip: reinforced polyamide
Screws: stainless steel
- Not supplied individually,
please contact us for details

Accessories

- GMC and GMK guides
- Fixing pins APB-F

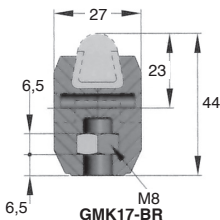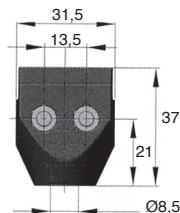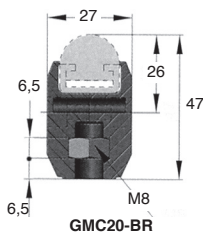

DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
GMC20-BR	For flat profile	0,03	✓	3,38 €
GMK17-BR	For round profile	0,03	✓	2,66 €

*Depending on availability - Dimensions in mm

Our other products



RHTplss
High Temperature
Castor, up to 200kg



PDD
Spring plunger, With
sensor adaptor



LWH
High rigidity linear
slide, Rail - from 9320
N to 71300 N



SHN
Hexagonal nut
DIN934, A2 Stainless
steel



BOXdh
Boxed set of
cylindrical dowel pins
DIN6325, Boxed set -
Solid DIN 6...



 
HDSS
Needle roller double
universal joint -
Stainless steel, Heavy
duty



HSE-HSB
Hexagonal spacer,
Steel



RBGtc
Swivel castor with
central hole, Steel -
grey rubber




LSM
Stainless steel 316L
leadscrew, Stainless



KH
Linear bearing, Light




 UCF
Cast iron flange
bearing unit, Cast iron



GMK17_P
Flat Guide, Flat guide
for conical profile

 Complementary products



GMC
Flat profile - Round
guide, Flat profile -
round guide



APB_F
Adjusting rod for
clamp - Male,
Threaded



STL
Guidance brush - Rail,
Rail



APB_BOU
Protective cap, Safety
cap