



# Guiding profile clamp




Plastic

**GMCBR**  
**GMKBR**

- Single clip for GMC and GMK guides
- Materials:  
Clip: reinforced polyamide  
Screws: stainless steel
- Not supplied individually,  
please contact us for details

## Accessories

- GMC and GMK guides
- Fixing pins APB-F

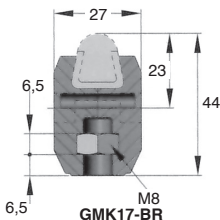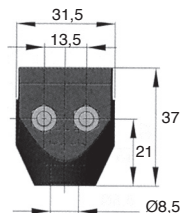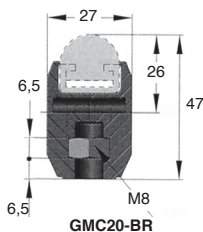

## DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
GMC20-BR	For flat profile	0,03	✓	3,38 €
GMK17-BR	For round profile	0,03	✓	2,66 €

\*Depending on availability - Dimensions in mm

## Our other products



RHTplss  
High Temperature  
Castor, up to 200kg



DOMI80  
Accessories, Clamping  
lever



PRF\_RR  
Coupling bar for  
aluminium profile,  
Coupling bar



ACL-APB  
Closing system for  
aluminium profile,  
Magnetic door stop



MHSC  
Single-disc flexible  
coupling, Single disk




PSG125  
Spur gear - precision  
range, Pre-hardened  
Steel 35NCD6



G1  
Steel spur gear, Steel  
20NCD2



 
PTA100ssEB  
Articulated foot with  
sheet metal base  
Ø100, Articulated foot



BH02  
Single housed bearing  
assembly, Bearing  
secured with circlips



 ATZY  
Diabolo shaped elasto  
mount, Steel




PRZ  
Wear strip for slat top  
chain, Z profile to be  
filled



BC3  
Panamech, Multi-  
Beam stainless steel,  
Stainless steel - with  
clampin...

## Complementary products

 

GMC  
Flat profile - Round  
guide, Flat profile -  
round guide



APB\_F  
Adjusting rod for  
clamp - Male,  
Threaded



STL  
Guidance brush - Rail,  
Rail



APB\_BOU  
Protective cap, Safety  
cap