



Guiding profile clamp




Plastic

GMCBR
GMKBR

- Single clip for GMC and GMK guides
- Materials:
Clip: reinforced polyamide
Screws: stainless steel
- Not supplied individually,
please contact us for details

Accessories

- GMC and GMK guides
- Fixing pins APB-F

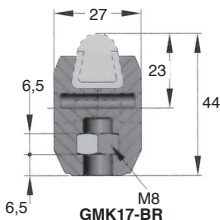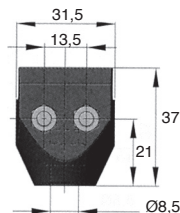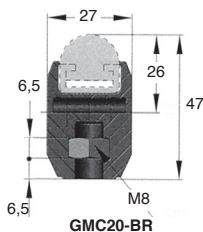

DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
GMC20-BR	For flat profile	0,03	✓	3,38 €
GMK17-BR	For round profile	0,03	✓	2,66 €

*Depending on availability - Dimensions in mm

Our other products



VPRA_M

Handwheel with handle,
Thermosetting plastic - galvanized steel hub



DEP

Tools Hygienic Usit® and Hygienic Design®, Socket for mounting Hyg...



LWH

High rigidity linear slide, Rail - from 9320 N to 71300 N



PSG35

Spur gear - precision range, Stainless steel 316



BLH60

Right angled gearbox, from 19 to 70 Nm



LVT

Miniature motorised actuator 2A, 2 amperes



ACLAPA

Magnetic stop for aluminium profile, Magnetic stop



BPVMss

Stainless steel miniature ball transfer unit, Miniature to screw



HAR9

Captive C washer, DIN 6371



TMR

Rigid manual tensioner, Adjustable



GCH


Linear ball slide Eco Range, economy



SH3

Parallel axis helical gear, Steel 20NCD2

 Complementary products



GMC

Flat profile - Round guide, Flat profile - round guide



APB_F

Adjusting rod for clamp - Male, Threaded



STL

Guidance brush - Rail, Rail



APB_BOU

Protective cap, Safety cap