



Guiding profile clamp




Plastic

GMCBR
GMKBR

- Single clip for GMC and GMK guides
- Materials:
Clip: reinforced polyamide
Screws: stainless steel
- Not supplied individually,
please contact us for details

Accessories

- GMC and GMK guides
- Fixing pins APB-F

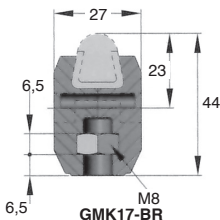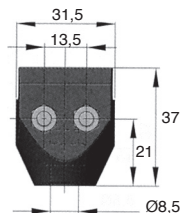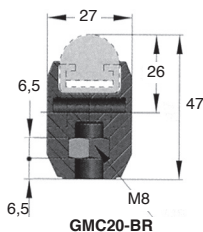

DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
GMC20-BR	For flat profile	0,03	✓	3,38 €
GMK17-BR	For round profile	0,03	✓	2,66 €

*Depending on availability - Dimensions in mm


Our other products



EKN
Bellows coupling
Gerwah®, from 0.5 to
12Nm



 RFK38C
Hypoid gearbox -
Stainless steel, up to
200 Nm




PF45
Worm and wheel gear
reducer, up to 40 Nm



PGB
Accessory-holder for
aluminium profile,
Tool holder



 IBjss
Ball and socket joint,
Stainless steel



PRZ
Wear strip for slat top
chain, Z profile to be
filled



SSHBRA
Stainless steel bevel
gear, 1,5:1 2:1 3:1



 
TOL
Swivel head, Long



KB_OP
Open precision linear
bearing, Precision -



GAC
Latch clamp with lock,
Lockable




RPP14
RPP heavy duty
timing belt, RPP14



RTE
Rotex®, jaw coupling,
steel

 Complementary products



GMC
Flat profile - Round
guide, Flat profile -
round guide



APB_F
Adjusting rod for
clamp - Male,
Threaded



STL
Guidance brush - Rail,
Rail



APB_BOU
Protective cap, Safety
cap