

Flat profile - Round guide



GMC
GMCss

For bottling and
packaging applications

- Guide profile for conveying products
- Materials:
 - Guide: DESLIDUR polyethylene (UHMW1000)
 - Support: steel or stainless steel
- Green



Accessories

- Fixing clips **GMC-BR**
- Supports **SDG**

Suitable for guiding
many different
products



Typical application

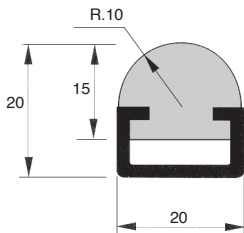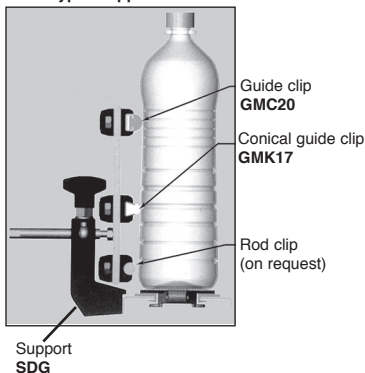

DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Length (mm)	Support material	Weight (kg/m)	Stock*	Price each
GMC20-3000	3000	Steel	0,70	✓	50,59 €
GMC20-3000/SS	3000	Stainless steel	0,70	✓	78,70 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



PPS1

Pinion shaft -
precision range,
Stainless steel



DOMI120

DOMILINE -
Accessories, Turntable



ESSB

Support base, Bipod
support base



HD

Universal joint - steel,
Needle bearings -
double



ESCON

Speed controller 5A
accessories, Kit of 4
cables for DC motor



GDR880

Straight guide,
Ranges 880 and 881



PM4

Worm, Machined
plastic (delrin)



PSG125

Spur gear - precision
range, Pre-hardened
Steel 35NCD6




BAC105

Storage bin, 8mm



PRF_CLIP_22

 Cable clip, For electric
and pneumatic cables



M1

Wheel, Machined
plastic (delrin)



S_ZZ

Ball bearing, Stainless
steel

Complementary products



GMC_GMK_BR

Clip for guide, Flat or
rounded



SDG

Guide support, Plastic



STL

Guidance brush, Rail



GDR880

Straight guide,
Ranges 880 and 881