



Guiding profile clamp




Plastic

GMCBR
GMKBR

- Single clip for GMC and GMK guides
- Materials:
Clip: reinforced polyamide
Screws: stainless steel
- Not supplied individually,
please contact us for details

Accessories

- GMC and GMK guides
- Fixing pins APB-F

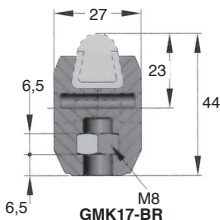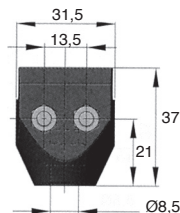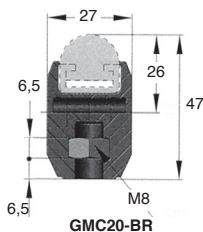

DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
GMC20-BR	For flat profile	0,03	✓	3,38 €
GMK17-BR	For round profile	0,03	✓	2,66 €

*Depending on availability - Dimensions in mm

Our other products



DTR

Tightener for chains,
Chain idler sprocket -
Steel



LC

Friction torque limiter,
190 to 1800 Nm



PSG125DL

Spur gear - precision
range, Peek



HSE-HSB

Spacer, Steel



DOMI50

DOMILINE -
Accessories, Turntable




MEP

Cylindrical revolving
handle, Fixed



CHA1056_U12

Screw-in hinge,
Section 60X60

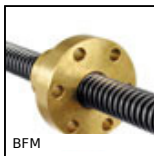

BFM

Trapezoidal nut,
Bronze - 1 thread



BHC

Truss-head screw BHC
- ISO 7380, Stainless
steel A2




CFUURSS

Cam follower,
Standard - stainless
steel



GRP2-14-C

Spring pin, splined
ISO 8742

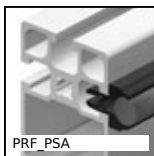

PRF_PSA

Roller for aluminium
profile, Shaft support

Complementary products



GMC

Guide, Flat profile -
round guide



APB_F

Rod for clamp,
Threaded



STL

Guidance brush, Rail



APB_BOU

Pin for clips, Safety
cap