



Guiding profile clamp




Plastic

GMCBR
GMKBR

- Single clip for GMC and GMK guides
- Materials:
Clip: reinforced polyamide
Screws: stainless steel
- Not supplied individually,
please contact us for details

Accessories

- GMC and GMK guides
- Fixing pins APB-F

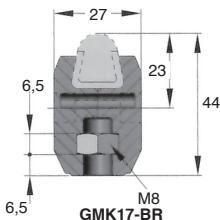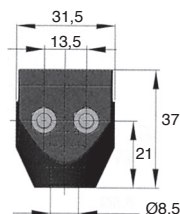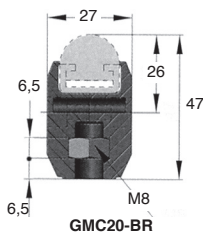

DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Type	Weight (kg)	Stock*	Price each 1 to 49
GMC20-BR	For flat profile	0,03	✓	3,38 €
GMK17-BR	For round profile	0,03	✓	2,66 €

*Depending on availability - Dimensions in mm

Our other products



NCT

Square tube connector, Fixed angle



EX

Optional shaft for E-type gear reducers, E Gearboxes double sided out...



LWL

Linear ball slide - Stainless steel balls, Rail - from 514 N to 1670...



ZG0

Plastic spur gear, Machined plastic (delrin)




DZY

Cylindrical stop, Steel



PF15

 Worm and wheel gear reducer, up to 3,75 Nm



P45

Worm and wheel gear reducer, up to 40 Nm



KBS_UU

Stainless steel closed precision linear bearing, Precision - stainless...



VTLM

3 lobed handle, Polyamide - Steel



PLMcr

Magnetic stud with hook, With hook



MCL


Cylindrical threaded sleeve, Cylindrical -



LRM2

Cylindrical bronze nut, Bronze - 2 threads

 Complementary products



GMC

Flat profile - Round guide, Flat profile - round guide



APB_F

Adjusting rod for clamp - Male, Threaded



STL

Guidance brush - Rail, Rail



APB_BOU

Protective cap, Safety cap