


Stainless steel

**GMKBRSS**  
**GMKBRDSS**


- For conical guiding profile
- Material: stainless steel 304

## Accessories

- GMC and GMK guides
- Fixing pins APBF

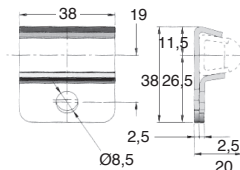

Single clip GMK17-BRS/SS

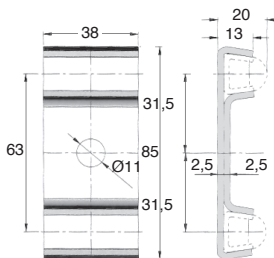

Double clip GMK17-BRD/SS

## DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Type	Weight (kg)		Price each 1 to 49
GMK17-BRS/SS	Single	0,05	✓	7,79 €
GMK17-BRD/SS	Double	0,13	✓	18,38 €

\*Depending on availability - Dimensions in mm

## Our other products



SSBRA  
Stainless steel bevel gear, 1:1



DOG258  
Motor-gearbox 12V and 24V DC, from 12 to 15 Nm



PSG125  
Spur gear - precision range, Case hardened steel 20NCd2




SHN  
Hexagonal nut DIN934, Steel (Class 6/8)



M2  
Worm and wheel set, Hardened steel



PSG15  
Spur gear - precision range, Stainless steel 316

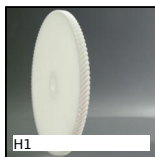

H1  
Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



SDG\_SS  
Universal adjustable guide support bracket, Stainless steel



DOMI50  
Accessories, Turntable



SEH  
Horizontal stirrup toggle clamp, Horizontal Latch clamp - stainless steel



PHT  
Pull handle, Up to 250 °C



NKX  
Combined bearing without inner ring, Needle and ball bearings


## Complementary products



 GMK17\_R  
Round guide, Round guide for conical profile



APB\_F  
Adjusting rod for clamp - Male, Threaded



GMK17\_P  
Flat Guide, Flat guide for conical profile



GMK17\_RG  
Joint for guiding profile, Rounded