


Stainless steel

**GMKBRSS**  
**GMKBRDSS**


- For conical guiding profile
- Material: stainless steel 304

## Accessories

- GMC and GMK guides
- Fixing pins APBF

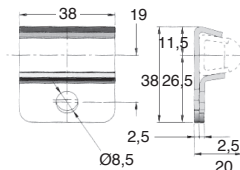

Single clip GMK17-BRS/SS

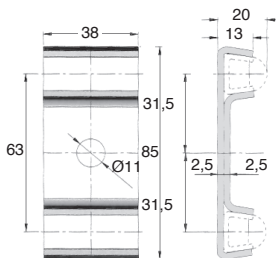

Double clip GMK17-BRD/SS

## DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Type	Weight (kg)		Price each 1 to 49
GMK17-BRS/SS	Single	0,05	✓	7,79 €
GMK17-BRD/SS	Double	0,13	✓	18,38 €

\*Depending on availability - Dimensions in mm

## Our other products



BEK

Bearing housing for miniature ballscrew, Bearing housing



PLM-SC

Magnetic stud with threaded hole, With threaded hole



DBL880

Idler for slat top chain, Ranges 880 and 881



GMK17\_RG

Joint for guiding profile, Rounded



PSG25S

Spur gear - precision range, Stainless steel 316



VPRA\_M

Handwheel with handle, Thermosetting plastic - stainless steel hub



HLUss

Spoked handwheel, Stainless steel 316



GE

Toggle latches, Standard



ACLEFS

Floor anchor for aluminium profile, Adjustable



PRF\_BP

Doorstop for aluminium profile, Swing door stop



Q6

Deep groove ball bearing, Steel



NAST

Cam follower without axial guide, With interior ring

## Complementary products



 
GMK17\_R

Round guide, Round guide for conical profile



APB\_F

Adjusting rod for clamp - Male, Threaded



GMK17\_P

Flat Guide, Flat guide for conical profile



GMK17\_RG

Joint for guiding profile, Rounded