


Stainless steel

GMKBRSS
GMKBRDSS


- For conical guiding profile
- Material: stainless steel 304

Accessories

- GMC and GMK guides
- Fixing pins APBF

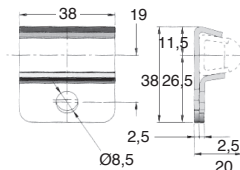

Single clip GMK17-BRS/SS

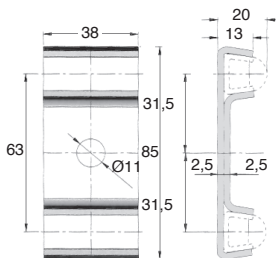

Double clip GMK17-BRD/SS

DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Type	Weight (kg)		Price each 1 to 49
GMK17-BRS/SS	Single	0,05	✓	7,79 €
GMK17-BRD/SS	Double	0,13	✓	18,38 €

*Depending on availability - Dimensions in mm

Our other products



BFM2

Flanged bronze nut,
Bronze - 2 threads



PW_PWG1

Worm - precision
range, Steel



T5P_T10P

Connecting plate for T
type timing belts, T5



M0

Worm and wheel set,
Machined plastic
(delrin)



ACLEPP

Right angled bracket
for aluminium profile,
2 holes



PT880

Drive sprocket for slat
top chain, Range 880



BSPT

Single rod clip, Round



CLM

Male clevis end,
Stainless steel short



INO

Internal gear, Steel
20NCD2



PM4

Worm and wheel set,
Hardened steel



UCF_SS

Stainless steel flanged
bearing, Stainless
steel



SDC

Positioning sleeve for
indexing pin, For pin
Ø4 to Ø12

Complementary products




GMK17_R

Round guide, Round
guide for conical
profile



APB_F

Adjusting rod for
clamp - Male,
Threaded

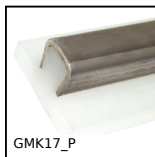

GMK17_P

Flat Guide, Flat guide
for conical profile



GMK17_RG

Joint for guiding
profile, Rounded