

# Brush strip



## GMK17 BROSSE

For bottling and  
packaging applications

- Brush for conveyor system

- Materials:

Conical profile: stainless steel

Body: DESLIDUR Polyethylene (UHMW1000)



Brush: Polyethylene

### Accessories

- Clip **GMK17**

- Fixing pin **APBF**

- Guide support **SDG**

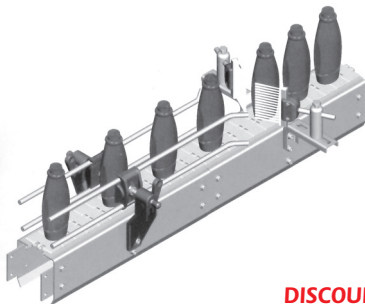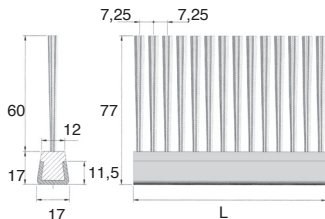

### DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Colour	L	Weight (kg)	Stock*	Price each
GMK17-BROSSE	White	500	0,36	✓	43,77 €

\*Depending on availability - Dimensions in mm

## Our other products



BMM

Knurled knob - male,  
Knurled



 
RPCtcss

Swivel castor with  
central hole, Stainless  
steel - Polyamide



GAL48\_OMNI

Omni-directional  
roller, Omni-  
directional



RPPM

RPP type belt per  
metre, RPP14 Steel  
cored polyurethane



SBRtool

Chain tool, Drive  
chain maintenance  
tools



PR125rehausse

Extension for  
articulated foot Ø123,  
articulated foot PR125



V3RA\_PT

3-spoked handwheel  
with handle,  
Polyamide



BOX-TOR-G

Box set of Nitrile O-  
rings in nitrile, 3.00 x  
1.50mm to 30.20 x  
3.00



CHNrb

Warning chain with  
red and white links,  
Steel



SERB

Cam latch, Cam latch



CHAsb63

Hinge without pin,  
Polymer pin hinge



PSG08

Spur gear - precision  
range, Case hardened  
steel 20NCD2

## Complementary products



 
GMC\_GMK\_BR

Guiding profile clamp,  
Flat or rounded



SDG

Adjustable guide  
support bracket,  
Plastic



STL

Guidance brush -  
Brush, Brush



GMK17\_RG

Joint for guiding  
profile, Rounded