



Flat guide for conical profile

For bottling and packaging applications

GMK17Pss



- Guide profile for conveying products
- Materials:
 - Guide: DESLIDUR polyethylene (UHMW1000)
 - Support: stainless steel

Accessories

- Fixing clip **GMK17-BR**, **GMK17-BRS/SS**, **GMK17-BRD/SS**
- Support **SDG**
- Link **GMK17-RG/SS**



stainless steel

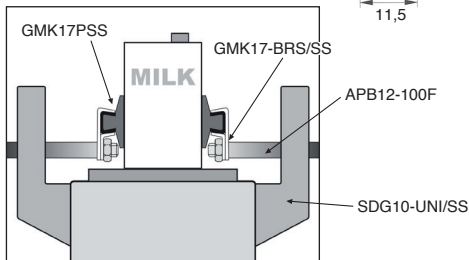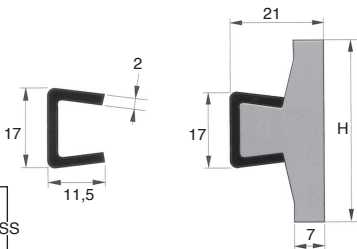

Typical application:
guiding food cartons

DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Colour	H	Length L(mm)	Weight (kg/m)	Stock*	Price each
GMK17-P40-3/SS	White	40	3000	0,88	✓	121,61 €
GMK17-P50-2/SS	White	50	2000	0,95	✓	144,86 €
GMK17-P60-2/SS	White	60	2000	1,02	✓	155,40 €

*Depending on availability - Dimensions in mm

Our other products



T39_T49

Extension spring in metre length steel, by the metre



GP

Spring loaded toggle latch, With padlock-holder



EP7

Electronic digital position indicator, 5 numbers



ATZYSS

Stainless steel diablo shaped elasto mount, Stainless steel



CLLCLLP

Clevis components, long version, Steel - long version



SHA

Handwheel without handle, Polyamide



HTD14M_85

HTD Heavy duty timing pulley, HTD14 Cast



PF40

Worm and wheel gear reducer, up to 18 Nm



LRR-53

Spring loaded latch, Spring return latch -



CAP815

Slim slat top chain stainless steel,



PSG2

Spur gear - precision range, Pre-hardened



BDP2R

Adjustable support arm, Increased grip

Complementary products



GMC_GMK_BR

Guiding profile clamp, Flat or rounded



GMK17_R

Round guide, Round guide for conical profile



SDG_SS

Universal adjustable guide support bracket, Stainless steel



GMK17_RG

Joint for guiding profile, Rounded