

# Round guide for conical profile



## GMK17RSS



For bottling and packaging applications

- Guide profile for conveying products
- Materials:
  - Guide: DESLIDUR Polyethylene (UHMW1000)
  - Support: stainless steel



### Accessories

- Fixing clip **GMK17-BR**, **GMK17-BRS/SS**, **GMK17-BRD/SS**
- Support **SDG**
- Link **GMK17-RG/SS**

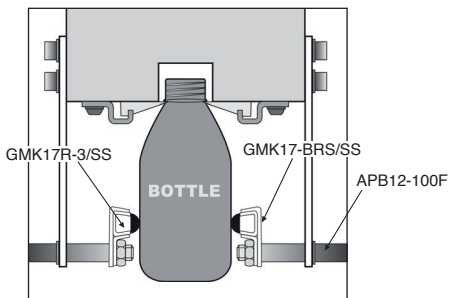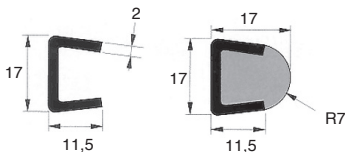

Typical application:  
guiding bottles

### DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Colour	Length L (mm)	Weight (kg/m)	Stock*	Price each
GMK17R-3/SS	White	3000	0,67	✓	71,05 €

\*Depending on availability - Dimensions in mm


## Our other products



PRF4590  
Standard aluminium  
profile, 45 x 90 mm



PVL  
Small lobed handle,  
Polyamide

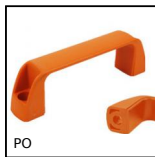

PO  
Pull handle - Multi-  
sector, Smooth hole



PCS625S  
Chain sprocket -  
Stainless steel,  
15.875mm (DIN  
08B-1)



H1  
Crossed helical gear  
crossed axis at 90°,  
Steel 20NCD2



VHEH  
Hexagonal headed  
screw with collar  
Hygienic Usit®,  
Stainless steel



WJUM20  
Drylin® W bearing  
block, Slide



MPE  
Hexagonal spacer,  
Steel




ACLBTS  
Closing system for  
aluminium profile,  
Spacer for spherical



MCL  
Cylindrical threaded  
sleeve, Cylindrical -  
stainless steel



SSB  
Stainless steel bevel  
gear, 1:1

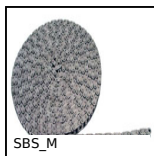


SBS\_M  
Single chain supplied  
by the metre,  
Stainless steel


## Complementary products



 GMC\_GMK\_BR  
Guiding profile clamp,  
Flat or rounded



 GMC  
Flat profile - Round  
guide, Flat profile -  
round guide



GMK17\_P  
Flat Guide, Flat guide  
for conical profile



GMK17\_BR  
Clamp for guiding  
profile, Rounded only  
- single