

# Round guide for conical profile



## GMK17RSS



### For bottling and packaging applications

- Guide profile for conveying products
- Materials:
  - Guide: DESLIDUR Polyethylene (UHMW1000)
  - Support: stainless steel



### Accessories

- Fixing clip **GMK17-BR**, **GMK17-BRS/SS**, **GMK17-BRD/SS**
- Support **SDG**
- Link **GMK17-RG/SS**

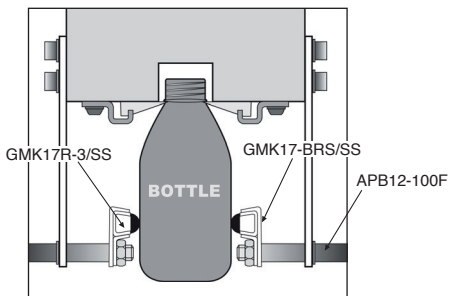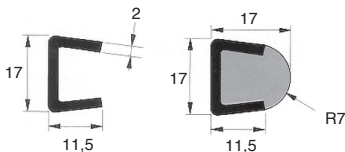

Typical application:  
guiding bottles

### DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Colour	Length L (mm)	Weight (kg/m)	Stock*	Price each
GMK17R-3/SS	White	3000	0,67	✓	71,05 €

\*Depending on availability - Dimensions in mm

**HPC**

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products




PW\_PWG2  
Worm - precision range, Steel



CAP805  
Slat top chain stainless steel, Large range 805



 NSP  
Right angled support clamp, Right angled support clamp



H2  
Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



GARBAB  
Lock pin for clamping, Ball lock pin



TBEBASE  
Base plate for economic mini-table, Allows X-Y cross tables



BIM  
Indexing plunger mini, miniature



BVR  
Adjustable screw stop, Steel




VAP  
Magnetic stud with central hole, With central hole



CRM  
Moulded nylon rack, Nylon



 DOMI120  
Accessories, Clamping lever




IN2  
Internal gear, Machined plastic (delrin)


## Complementary products



 GMC\_GMK\_BR  
Guiding profile clamp, Flat or rounded



 GMC  
Flat profile - Round guide, Flat profile - round guide



GMK17\_P  
Flat Guide, Flat guide for conical profile



GMK17\_BR  
Clamp for guiding profile, Rounded only - single