

Round guide for conical profile



GMK17RSS



For bottling and packaging applications

- Guide profile for conveying products
- Materials:
 - Guide: DESLIDUR Polyethylene (UHMW1000)
 - Support: stainless steel



Accessories

- Fixing clip **GMK17-BR**, **GMK17-BRS/SS**, **GMK17-BRD/SS**
- Support **SDG**
- Link **GMK17-RG/SS**

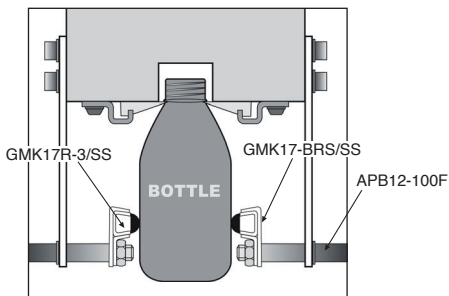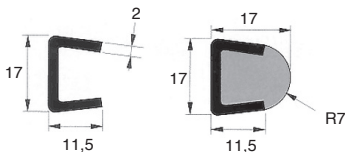

Typical application:
guiding bottles

DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Colour	Length L (mm)	Weight (kg/m)	Stock*	Price each
GMK17R-3/SS	White	3000	0,67	✓	71,05 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



CLAT

Clamping lever
Hygienic Usit® -
male, Stainless steel



BPH

Ball transfer unit plain
fit, High



BABS303

303 Stainless steel
compact ball pin,
Stainless steel 303



RT70

Self-centering locking
Assembly,
Medium/high torque



BAN

Angular clamp,
Adjustable



DOMI120

Domino 120
adjustable slide, Slide
DOMILINE 120



BOX-TOR-H

Box set of Nitrile O-
rings in nitrile, 3.00 x
2.00mm to 45.20 x
4.00



PRF_FIX_ANG

Fastener for
aluminium profile,
Angular joint



TFR

Rigid manual
tensioner, Fixed



DOMI30

Accessories, Plate



PLM-20SC

Threaded cylindrical
magnet, With



AFA

 
Locking pin, with ring

Complementary products




GMC_GMK_BR

Guiding profile clamp,
Flat or rounded



GMC

 Flat profile - Round
guide, Flat profile -
round guide



GMK17_P

Flat Guide, Flat guide
for conical profile



GMK17_BR

Clamp for guiding
profile, Rounded only
- single