

Round guide for conical profile



GMK17RSS



For bottling and packaging applications

- Guide profile for conveying products
- Materials:
 - Guide: DESLIDUR Polyethylene (UHMW1000)
 - Support: stainless steel



Accessories

- Fixing clip **GMK17-BR**, **GMK17-BRS/SS**, **GMK17-BRD/SS**
- Support **SDG**
- Link **GMK17-RG/SS**

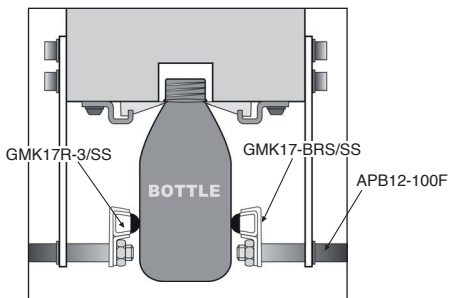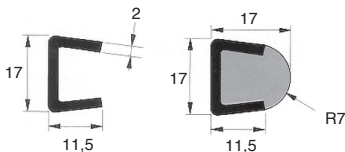

Typical application:
guiding bottles

DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Colour	Length L (mm)	Weight (kg/m)	Stock*	Price each
GMK17R-3/SS	White	3000	0,67	✓	71,05 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com


Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



NPCR

Adjustable cell support, Adjustable

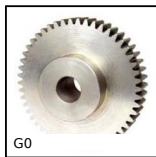

G0

Steel spur gear, Steel 20NCD2



GG3

Ground spur gear, Heat treated steel



MHXred

Reducing sleeve male/female, Hexagonal - steel



RVM25

Manually operated gearbox, Bevel



CHM110

Worm and wheel gear reducer, up to 980 Nm



CHA35

Hinge for aluminium profile, Hinge



ACLLPP

Latch for aluminium profile, Spring operated latch



PCH

Knob for gripping, Mushroom



ZG0

Plastic spur gear, Machined plastic (delrin)



METEB

Self-lubricating blanks, Bronze BP25



PFC

 
Fixed rubber levelling foot, Levelling support for small parts

Complementary products




GMC_GMK_BR

Guiding profile clamp, Flat or rounded



GMC

 Flat profile - Round guide, Flat profile - round guide



GMK17_P

Flat Guide, Flat guide for conical profile



GMK17_BR

Clamp for guiding profile, Rounded only - single