


Joint for guiding profile



GMKRGss

Stainless steel

- For conical guiding profile
- Material: stainless steel 304
- For connecting GMK17 profiles

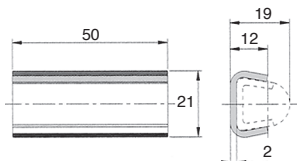


DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Weight (kg)	Stock*	Price each 1 to 49
GMK17-RG/SS	0,03	✓	5,99 €

*Depending on availability - Dimensions in mm

Typical applications

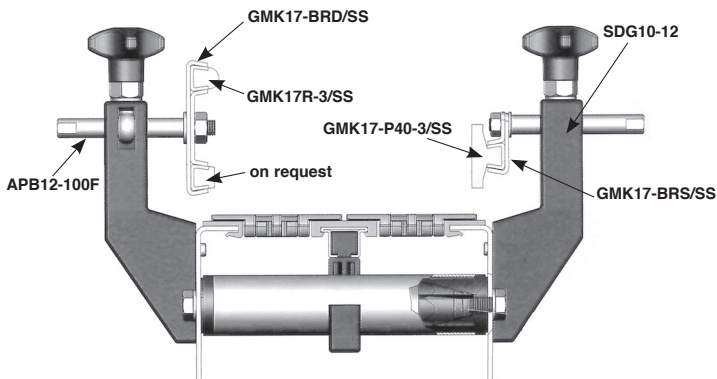

Our other products



Stainless steel pull handle, Stainless steel



Ball transfer unit light duty, Light



Manual leadscrew table with opposing threads, 5kg



Spur round rack, Steel - module 1-6



Adjustable guide support bracket, Plastic



Connecting plate for AT type timing belts, AT10



Worm and wheel set, Machined plastic (delrin)



Hose clamp, Box set of stainless steel hose clamps



 
Spur gear - precision range, Pre-hardened



Swivel castor with central hole, Steel -



Moulded plastic bevel gear (nylon), 2:1




Worm and wheel gear reducer, up to 5 Nm

Complementary products



 Round guide, Round guide for conical profile



Flat Guide, Flat guide for conical profile



Brush strip, Cone-shaped - brush



Clamp for guiding profile, Rounded only - single