


Joint for guiding profile



GMKRGss

Stainless steel

- For conical guiding profile
- Material: stainless steel 304
- For connecting GMK17 profiles

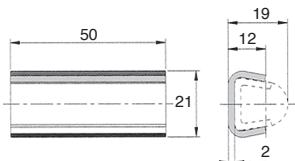


DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request


Part number	Weight (kg)	Stock*	Price each 1 to 49
GMK17-RG/SS	0,03	✓	5,99 €

*Depending on availability - Dimensions in mm

Typical applications

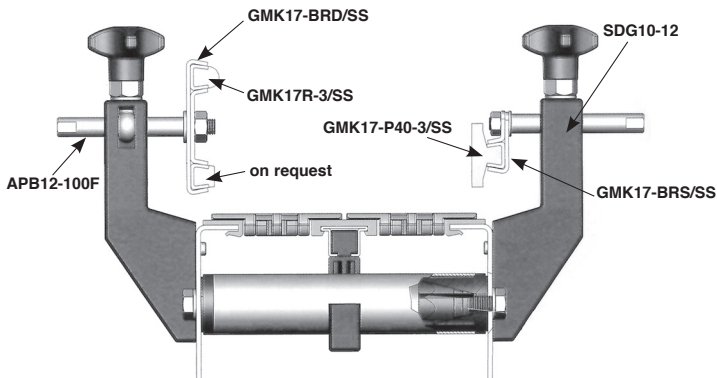

Our other products

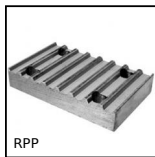

RPP

Connecting plate for RPP type timing belts, RPP8



INS_SS

Self tapping stainless steel insert, 316 stainless steel



CLG1

Moulded plastic spur gear, Moulded plastic (nylon)




CHMR75

Worm and wheel gear reducer, up to 298 Nm



PSG125S

Spur gear - precision range, Stainless steel 316

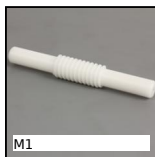


M1

Worm and wheel set, Machined plastic (delrin)



PGT

Sliding profile, Sliding panel support

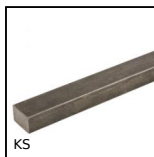

KS

Keysteel, Steel - Keystock



CHML63

Worm and wheel gear reducer, up to 138 Nm - Integrated



SLB

Indexing plunger, stainless steel



CLSCLP

Clevis components, short version, Steel - short range



HFL


One way needle bearing, Needle bearing

Complementary products



GMK17_R

Round guide, Round guide for conical profile

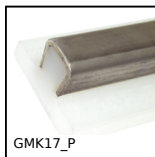

GMK17_P

Flat Guide, Flat guide for conical profile



GMK17_BROSSE

Brush strip, Cone-shaped - brush



GMK17_BR

Clamp for guiding profile, Rounded only - single