


Joint for guiding profile



GMKRGss

Stainless steel

- For conical guiding profile
- Material: stainless steel 304
- For connecting GMK17 profiles

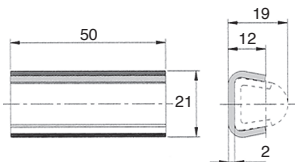


DISCOUNTS

Qty	1+	50+	100+	200+
Disc.	List	-5%	-10%	On request

Part number	Weight (kg)	Stock*	Price each 1 to 49
GMK17-RG/SS	0,03	✓	5,99 €

*Depending on availability - Dimensions in mm


Typical applications

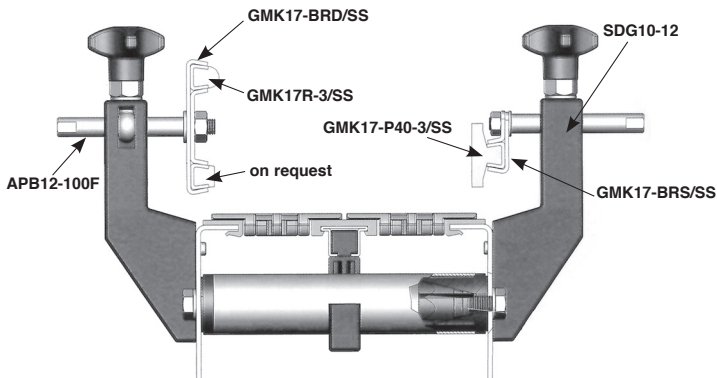

Our other products



 RFK48B
Hypoid gearbox -
Stainless steel, up to
350 Nm



RPPM
RPP type belt per
metre, RPP5 Steel
cored polyurethane



CHB
Worm and wheel gear
reducer, up to 73 Nm



BFM
Flanged bronze nut,
Bronze - 1 thread



BTC
End cap for square
tube, Standard



GPB
Threaded spherical
knob, Moulded thread



INO
Internal gear, Steel
20NCD2



 
PRESS5HR
Manual workbench
press, Force up to
500kg



NKX
Combined bearing
without inner ring,
Needle and ball
bearings



VTAP
Magnetic head screw,
With rubber coating
With rubber coating



MLY
Bow shackle with eye
bolt, Steel




CHM30-MOT
Asynchronous AC
motorgearboxes 0.09
to 0.22kW, 0.09 to
0.22kW

Complementary products



 GMK17_R
Round guide, Round
guide for conical
profile



GMK17_P
Flat Guide, Flat guide
for conical profile



GMK17_BROSSE
Brush strip, Cone-
shaped - brush



GMK17_BR
Clamp for guiding
profile, Rounded only
- single