

# Brush strip



## GMK17 BROSSE

For bottling and  
packaging applications

- Brush for conveyor system

- Materials:

Conical profile: stainless steel

Body: DESLIDUR Polyethylene (UHMW1000)



Brush: Polyethylene

### Accessories

- Clip **GMK17**

- Fixing pin **APBF**

- Guide support **SDG**

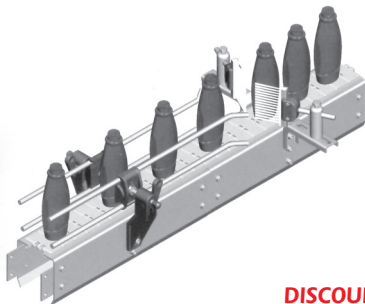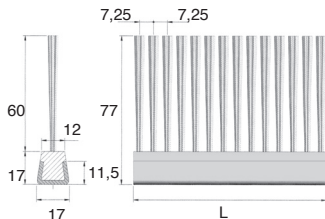

### DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Colour	L	Weight (kg)	Stock*	Price each
GMK17-BROSSE	White	500	0,36	✓	43,77 €

\*Depending on availability - Dimensions in mm

## Our other products



SC2

2 part rigid shaft clamp, Clamping jaw



DOMI120

Accessories, Plate



FF10

Offset spur gear reducer, from 0.78 to 3.70 Nm



PSG255

Spur gear - precision range, Stainless steel 316



TPR

High helix leadscrew, Leadscrew only - up to 40mm per rotation



MEB

Moulded plastic bevel gear (nylon), 1:1



SLH

Horizontal toggle clamp, Horizontal Lever Clamp - steel



BAC105

Storage bin, 8mm



HRV

V-rail guidance Simple Select® system, Rail with



SVT20

Screwjack with travelling screw, with translating screw



BC2

Panamech, Multi-Beam, Aluminium - with clamping jaw



GP

Spring loaded toggle latch, With padlock-holder

## Complementary products



GMC\_GMK\_BR

Guiding profile clamp, Flat or rounded



SDG

Adjustable guide support bracket, Plastic



GMK17\_RG

Joint for guiding profile, Rounded



GMK17\_BR

Clamp for guiding profile, Rounded only - single