



Flat guide for conical profile



For bottling and packaging applications

GMK17Pss

- Guide profile for conveying products
- Materials:
 - Guide: DESLIDUR polyethylene (UHMW1000)
 - Support: stainless steel

Accessories

- Fixing clip **GMK17-BR**, **GMK17-BRS/SS**, **GMK17-BRD/SS**
- Support **SDG**
- Link **GMK17-RG/SS**

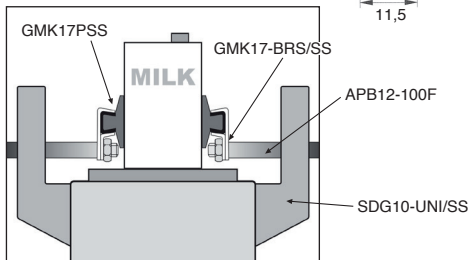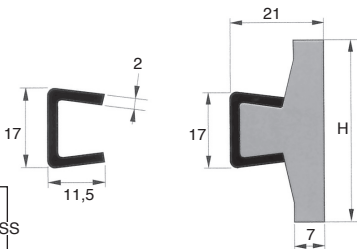

Typical application:
guiding food cartons

DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Colour	H	Length L(mm)	Weight (kg/m)	Stock*	Price each
GMK17-P40-3/SS	White	40	3000	0,88	✓	121,61 €
GMK17-P50-2/SS	White	50	2000	0,95	✓	144,86 €
GMK17-P60-2/SS	White	60	2000	1,02	✓	155,40 €

*Depending on availability - Dimensions in mm

Our other products



MDR

Dee shackle with eye bolt, Steel



MDB_MTB

Moulded plastic bevel gear (nylon), 2:1



PTKFss

Cap nut for foot for the food industry, Stainless steel blind nut - ...



DOMI50

Connecting kits, XY linking kit



DGSI

Female rod ends, Steel / steel - Economy range



PSG08

Spur gear - precision range, Case hardened steel 20NCD2



EMAS

Antistatic knurled nut, Antistatic



NCT

Square tube connector, Fixed angle



 
SHN

Hexagonal nut, DIN934, A2 Stainless



BPQ

Quadro linear ball bearing unit, Included



PX_PO

Carrying handle, back-plated



SHTC

Drylin® Linear table, Maintenance free

Complementary products



GMC_GMK_BR

Guiding profile clamp, Flat or rounded



GMK17_R

Round guide, Round guide for conical profile



SDG_SS

Universal adjustable guide support bracket, Stainless steel



GMK17_RG

Joint for guiding profile, Rounded