

Round guide for conical profile



GMK17RSS



For bottling and packaging applications

- Guide profile for conveying products
- Materials:
 - Guide: DESLIDUR Polyethylene (UHMW1000)
 - Support: stainless steel



Accessories

- Fixing clip **GMK17-BR**, **GMK17-BRS/SS**, **GMK17-BRD/SS**
- Support **SDG**
- Link **GMK17-RG/SS**

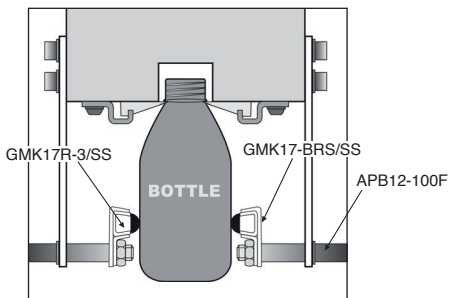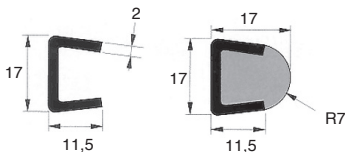

Typical application:
guiding bottles

DISCOUNTS

Qty	1+	2+	4+	10+
Disc.	List	-10%	-15%	On request

Part number	Colour	Length L (mm)	Weight (kg/m)	Stock*	Price each
GMK17R-3/SS	White	3000	0,67	✓	71,05 €

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

 
www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products




EKONSL
Silicone conical elastomer buffer, Female mounting



H2
Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



 RAS
90° ball and socket joints DIN71802, Stainless steel



RPP8
RPP heavy duty timing belt, RPP8



CLG2
Moulded plastic spur gear, Moulded plastic (nylon)



BMM
Knurled knob - male, Knurled



CDGamme
Compression spring DIN2095, DIN 2095



WING
Manually tightened wing nut, Steel (ANSI B18-17)



DOMI_MD
Domino rotary table, 40/1



ACAss
Stainless steel splined shaft, Stainless steel



RFVbr
Stainless steel reaction arm,

 


CHALss
Piano hinge, Stainless steel


Complementary products



GMC_GMK_BR
Guiding profile clamp, Flat or rounded



 GMC
Flat profile - Round guide, Flat profile - round guide



GMK17_P
Flat Guide, Flat guide for conical profile



GMK17_BR
Clamp for guiding profile, Rounded only - single