

Recommended in absence of seal

GP22
GP23

- Wide positioning tolerances
- Very adaptable
- Suitable for vibrations
- Materials:
White zinc steel or stainless steel 303

Assembly



- When used with AC122 hook, dimension X= 87mm to withstand a tension of 350N
- Dimension X taken on the first hole of the hook.

Info

- Not sold individually, please contact us for details

Accessory

- Hooks AC122 (t.imagetome1 p.125)

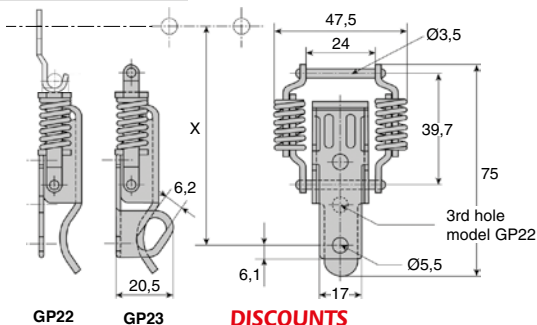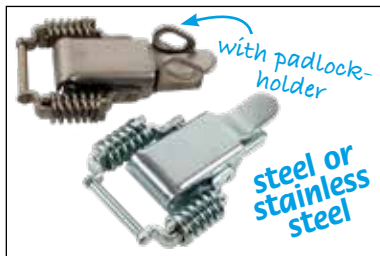

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Material	Wire Ø	Lever thickness	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
With padlock holder								
GP22-ZB	Steel	1,7	20/10th	25/10th	450	75	✓	7,58 €
GP22-SS	Stainless steel	2,7	20/10th	25/10th	450	75	✓	15,64 €
Without padlock holder								
GP23-ZB	Steel	2,5	20/10th	25/10th	450	75	✓	7,80 €
GP23-SS	Stainless steel	3,5	20/10th	25/10th	450	75	✓	16,11 €

*Subject to availability - Dimensions in mm

Our other products



ADL_F

Female eye bolt conforms to DIN582, Stainless steel



PTAF100-PAMF100

Articulated fixable foot with pressed base Ø100, Ø 100



SCR

Suction cup threaded insert, Adaptator for insert



PRES

Manual workbench press accessory for PRES-3HR end PRES-4HR, Set of s...



PRF_PL_9090

Joining plate for aluminium profile, joint plate - 90x90 mm



SSG1_304L

Stainless steel spur gear, Stainless steel 304L



BS2

Panamech, Multi-Beam, Aluminium - with set screw



CF

Cam follower, Standard - steel



SCH

Horizontal hook toggle clamp, Horizontal Hook



PCS75K

Chain sprocket with hardened teeth, 19.05mm (DIN12B-1)



DOMI50

Accessories, Fixing kit



PR125rehausse

Extension for articulated foot Ø123, articulated foot PR125

Complementary products



AC

Strike for toggle latch, 12,13,18 and 20mm