

Recommended in absence of seal

GP22
GP23

- Wide positioning tolerances
- Very adaptable
- Suitable for vibrations
- Materials:
White zinc steel or stainless steel 303

Assembly



- When used with AC122 hook, dimension X= 87mm to withstand a tension of 350N
- Dimension X taken on the first hole of the hook.

Info

- Not sold individually, please contact us for details

Accessory

- Hooks AC122 (t.imagetome1 p.125)

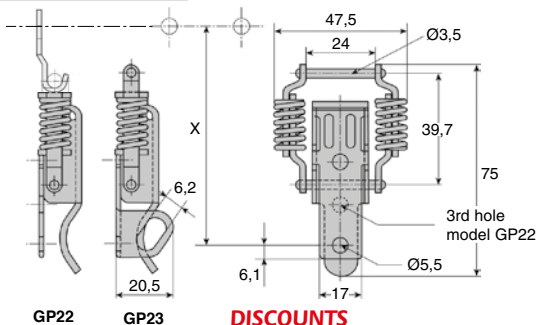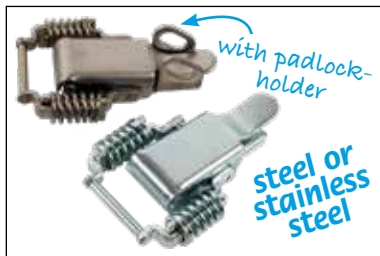

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request


Part number	Material	Wire Ø	Lever thickness	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
With padlock holder								
GP22-ZB	Steel	1,7	20/10th	25/10th	450	75	✓	7,58 €
GP22-SS	Stainless steel	2,7	20/10th	25/10th	450	75	✓	15,64 €
Without padlock holder								
GP23-ZB	Steel	2,5	20/10th	25/10th	450	75	✓	7,80 €
GP23-SS	Stainless steel	3,5	20/10th	25/10th	450	75	✓	16,11 €

*Subject to availability - Dimensions in mm

Our other products



G-ECO
Eco range Spur gear,
Steel C45

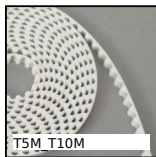

T5M T10M
T type timing belt per
metre, T10 Steel
cored polyurethane



PTAF80-PAMF80
Articulated fixable
foot with pressed
base Ø80, Ø 80



GLP
Small 6 lobe threaded
handle - male,
Technopolymer - Steel




GG2
Ground spur gear,
Heat treated steel



CHAFR-MINI
Miniature friction
hinge, Friction



DCA
Suction cup, 1.5
bellows, silicon

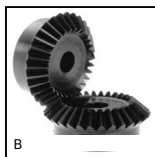

B
Steel bevel gear, 1:1




VTLF
3 lobed handle,
Polyamide - Brass



MPB
Hexagonal spacer,
Brass



PLC_PLT
Magnetic stud with
threaded hole, With

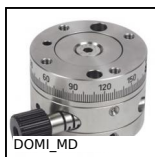


DOMI_MD
Domino rotary table,
55/1

Complementary products



 AC
Strike for toggle latch,
12,13,18 and 20mm



AC
Strike for toggle latch,
20mm



GP75
Spring loaded toggle
latch, Standard
(GP75)