

Recommended in absence of seal

**GP22**  
**GP23**

- **Wide positioning tolerances**
- Very adaptable
- Suitable for vibrations
- Materials:

White zinc steel or stainless steel 303

## Assembly


- When used with **AC122** hook, dimension  $X = 87\text{mm}$  to withstand a tension of 350N
- Dimension  $X$  taken on the first hole of the hook.

## Info

- **Not sold individually, please contact us for details**

## Accessory

- Hooks **AC122** (t.imagetome1 p.125)

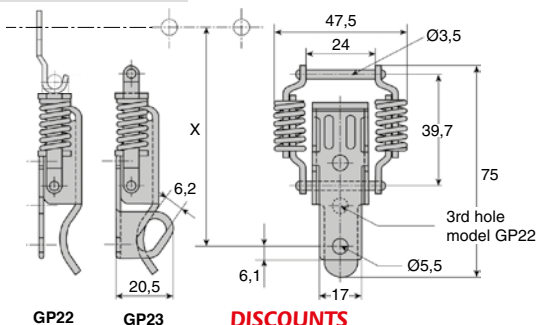

## DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Material	Wire Ø	Lever thickness	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
<b>With padlock holder</b>								
GP22-ZB	Steel	1,7	20/10th	25/10th	450	75	✓	7,58 €
GP22-SS	Stainless steel	2,7	20/10th	25/10th	450	75	✓	15,64 €
<b>Without padlock holder</b>								
GP23-ZB	Steel	2,5	20/10th	25/10th	450	75	✓	7,80 €
GP23-SS	Stainless steel	3,5	20/10th	25/10th	450	75	✓	16,11 €

\*Subject to availability - Dimensions in mm

## Our other products



KB\_UU  
Closed linear  
precision bearing,  
Precision - steel



MFBS  
Stainless steel flexible  
bellows coupling,  
Stainless steel - with  
se...



UTKpwrr  
V shaped channel  
UtiliTrak®, V rail



BLHB30  
Right angled gearbox,  
bored shafts, up to  
4.47 Nm



HTD14M\_85  
HTD Heavy duty  
timing pulley, HTD14  
Cast



YG1  
HEAVY DUTY spur  
gear, Steel 35NCD6



CM  
Tools Hygienic Usit®  
and Hygienic  
Design®,  
Combination spanner




GCA  
Linch pin, Linch



PTA100ssEB  
Articulated foot with  
sheet metal base  
Ø100, 15000N



GSA\_A  
Adjustable gas spring,  
Steel

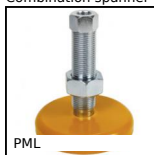

PML  
Solid foot mount for  
heavy loads, Ø 100,  
120 or 150




PSG08  
Spur gear - precision  
range, Pre-hardened  
Steel 35NCD6

## Complementary products



 AC  
Strike for toggle latch,  
12,13,18 and 20mm



AC  
Strike for toggle latch,  
20mm