

Recommended in absence of seal

GP22
GP23

- **Wide positioning tolerances**
- Very adaptable
- Suitable for vibrations
- Materials:
White zinc steel or stainless steel 303

Assembly



- When used with **AC122** hook, dimension $X = 87\text{mm}$ to withstand a tension of 350N
- Dimension X taken on the first hole of the hook.

Info

- **Not sold individually, please contact us for details**

Accessory

- Hooks **AC122** (t.imagetome1 p.125)

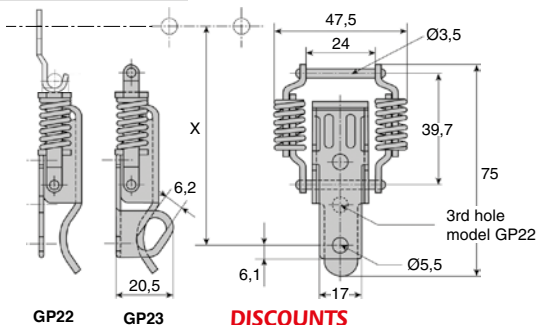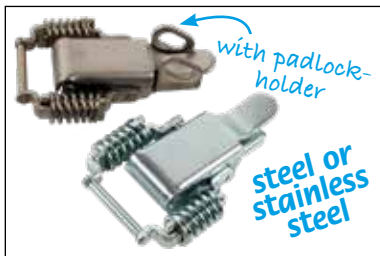

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Material	Wire Ø	Lever thickness	Back-plate thickness	Max. tension (N)	Weight (g)	Stock*	Price each 1 to 50
With padlock holder								
GP22-ZB	Steel	1,7	20/10th	25/10th	450	75	✓	7,58 €
GP22-SS	Stainless steel	2,7	20/10th	25/10th	450	75	✓	15,64 €
Without padlock holder								
GP23-ZB	Steel	2,5	20/10th	25/10th	450	75	✓	7,80 €
GP23-SS	Stainless steel	3,5	20/10th	25/10th	450	75	✓	16,11 €

*Subject to availability - Dimensions in mm

Our other products



CHAFR
Adjustable friction hinges, Friction




SEV
Vertical stirrup toggle clamp, Vertical Latch Clamp - steel



ACLRP
Wheel for aluminium profile, Integrated bearing



BABreceptacle
Ball pin socket, Socket

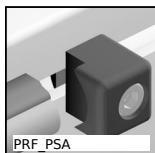

PRF_PSA
Shaft support for aluminium profile, Shaft stop




BUT
Panel stop, Panel stop



CHAC4040NP
Square hinge with riveted pin, not drilled, Square with riveted pin,...



BPM-Z
Plastic slotted spring plunger with ball tip, Plastic body + plastic...

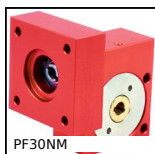

PF30NM
Worm and wheel gear reducer, up to 8.8 Nm



CQA20
Adjustment slide-system miniature, 20



LRRALatch with locking system, Aluminium




GLP
Small 6 lobe threaded handle - male, Technopolymer - Steel

Complementary products



AC
Strike for toggle latch, 12,13,18 and 20mm

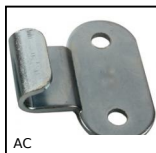

AC
Strike for toggle latch, 20mm



GP75
Spring loaded toggle latch, Standard (GP75)