

Sprung toggle latch with connecting link

GP75

Recommended for applications with no seal


- High retaining strength for a spring latch
- Lever can be locked to the mounting bracket by retractable handle
- Easy operation of the release handle
- Can be locked
- Large spring range
- Wide positioning tolerance
- Materials:
 - White zinc plated steel
 - 18/8 stainless steel, natural finish

Installation

- Approximate mounting dimension: Using an AC144 catch plate, X = 82.5 mm for a tension of about 550N

Accessories

- AC144-ZZB and AC144-SS catch plates

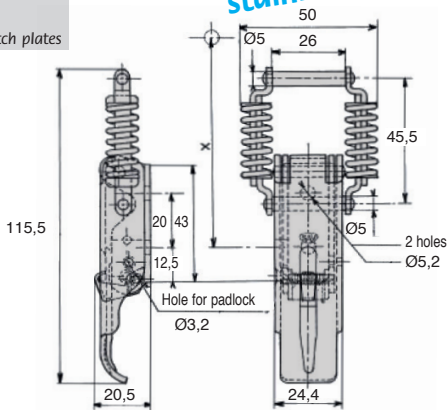

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Wire Ø	Lever thickness	Mounting plate thickness	Max tension (N)	Weight (g)	Stock*	Price each 1 to 50
GP75-ZB	Steel	5,00	20/10th	20/10th	750	125	✓	10,87 €
GP75-SS	Stainless steel	5,00	20/10th	20/10th	750	125	✓	18,60 €

 
All dimensions in mm

Our other products



FBL6000_K1

Brush strip per meter
PA6 fibres Ø0.2 to
Ø0.3, Black polyamide
6 -...




T5_11

T type timing pulley,
T5 aluminium



MHXred

Reducing sleeve
male/female,
Hexagonal - stainless
steel

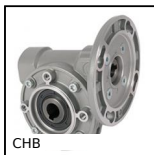

CHB

Worm and wheel gear
reducer, up to 73 Nm



TB8

Cylindrical roller
thrust bearing, Steel



METC

Flanged sintered
bronze bush, Self-
lubricating sintered
bronze



PPS

Lifting ring, Universal
threaded



DBL820

Idler for slat top
chain, Ranges 820
and 815



NCT

Square tube
connector, Fixed



BABss

303 Stainless steel
ball pin, 303 Stainless



DILC

Indexing plunger with
cam, with cam



DILC

Indexing plunger with
cam, with cam

Complementary products



AC144

Strike for toggle latch,
22mm



GP75

Spring loaded toggle
latch, Standard
(GP75)



GE

Toggle latches,
Standard



GE14

Toggle latches, With
padlock-holder