

Sprung toggle latch with connecting link

GP75

Recommended for applications with no seal


- High retaining strength for a spring latch
- Lever can be locked to the mounting bracket by retractable handle
- Easy operation of the release handle
- Can be locked
- Large spring range
- Wide positioning tolerance
- Materials:
 - White zinc plated steel
 - 18/8 stainless steel, natural finish

Installation

- Approximate mounting dimension: Using an AC144 catch plate, X = 82.5 mm for a tension of about 550N

Accessories

- AC144-ZZB and AC144-SS catch plates

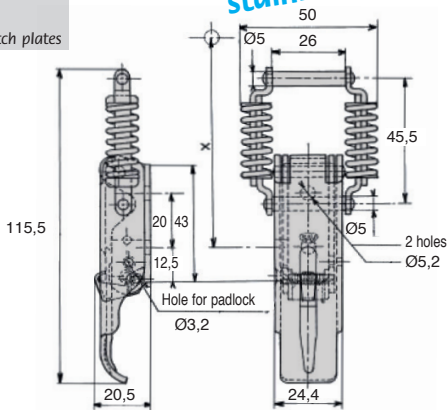

DISCOUNTS

Qty	1+	51+	101+	250+	400+
Disc.	List	-10%	-15%	-20%	On request

Part N°	Material	Wire Ø	Lever thickness	Mounting plate thickness	Max tension (N)	Weight (g)	Stock*	Price each 1 to 50
GP75-ZB	Steel	5,00	20/10th	20/10th	750	125	✓	10,87 €
GP75-SS	Stainless steel	5,00	20/10th	20/10th	750	125	✓	18,60 €

All dimensions in mm

Our other products



 
MC
Self-compensating shock-absorber, Self-compensating - without adjust...



S_2RS
Deep groove ball bearing, Stainless steel



SEH
Horizontal stirrup toggle clamp, Horizontal Latch clamp - stainless ...



RPP14
RPP heavy duty timing belt, RPP14



BCM_T
Driving collar, Driving collar



 
HBM
Adjustment bushing for half-rail guide, Adjustment bushing



PO
Pull handle - Multi-sector, Smooth hole



PENC
Recessed handle, clip-in



BLHM20
Right angled gearbox, double output shafts, up to 1.77 Nm



PGR
Folding revolving handle for handwheel, Folding



PR85
Articulated foot Ø83, Ø 83



CLLCLLP
Clevis components, long version, Steel - long range

Complementary products



AC144
Strike for toggle latch, 22mm



GP75
Spring loaded toggle latch, Standard (GP75)



GP
Spring loaded toggle latch, With padlock-holder



GE1006
Elastic ringed latch, Hooks into a slot holder