

Threaded spherical knob



GPB

Technopolymer

- Spherical knob with moulded thread or brass insert
- Small central groove
- Material :
Black Duroplast with brass insert

Option



- Stainless steel or polyamide colored insert on quantities

Info.

- Not sold individually, please contact us for details

Moulded thread

Brass insert

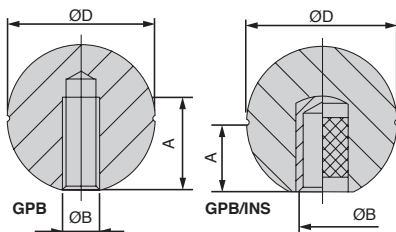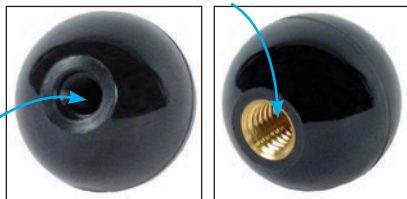


DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	ØB	Stock*	Price each 1 to 9
Moulded thread					
GPB19-M4	19	10	M4	✓	1,61 €
GPB19-M5	19	10	M5	✓	1,61 €
GPB19-M6	19	10	M6	✓	1,72 €
GPB25-M6	25	17	M6	✓	1,90 €
GPB25-M8	25	17	M8	✓	1,90 €
GPB32-M8	32	20	M8	✓	2,11 €
GPB32-M10	32	20	M10	✓	2,11 €
GPB32-M12	32	20	M12	✓	2,11 €
GPB41-M10	41	20	M10	✓	2,80 €
GPB41-M12	41	20	M12	✓	2,80 €
GPB47-M14	47	23	M14	✓	3,76 €
Threaded insert					
GPB19-M6/INS	19	9	M6	✓	2,73 €
GPB25-M8/INS	25	15	M8	✓	2,87 €
GPB32-M8/INS	32	15	M8	✓	2,94 €
GPB32-M10/INS	32	16	M10	✓	3,27 €
GPB41-M10/INS	41	16	M10	✓	4,31 €
GPB41-M12/INS	41	18	M12	✓	5,02 €

*Depending on availability - Dimensions in mm

 Our other products



TBV

Manual lifting tables,
7kg



PW_PWG25

Worm - precision
range, Stainless steel



DB_ECO

Eco. range steel bevel
gear, 2:1



IBJ

180° ball and socket
joints, Steel



RBGpl

Swivel castor with
plate, Steel - grey
rubber



 
CHAGC-AL

Screw-in garnet
hinge, Screw-on



BPQ

Quadro linear ball
bearing unit, Included
4 linear ball bearings



PRF_PSA

Shaft support for
aluminium profile,
Shaft support



BUH77

Motor-gearbox 12V
and 24V DC, from 0.1
to 2 Nm



ZDB

Machined plastic
bevel gear , 2:1



SSDB

Stainless steel bevel
gear, 2:1



BH02

Single housed bearing
assembly, Bearing
secured with circlips

Complementary products



GPB

Threaded spherical
knob, Moulded thread



PCH

Knob for gripping,
Mushroom



GPBSS

Threaded spherical
knob, Stainless steel
304



VTLF

3 lobed handle,
Polyamide - Brass