

# Threaded spherical knob



## GPB

## Technopolymer

- Spherical knob with moulded thread or brass insert
- Small central groove
- Material :  
Black Duroplast with brass insert

### Option



- Stainless steel or polyamide colored insert on quantities

### Info.

- Not sold individually, please contact us for details

Moulded thread

Brass insert

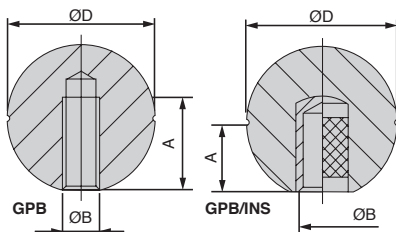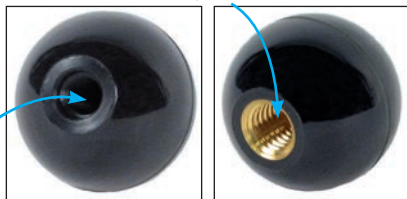

### DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	ØB	Stock*	Price each 1 to 9
<b>Moulded thread</b>					
GPB19-M4	19	10	M4	✓	1,61 €
GPB19-M5	19	10	M5	✓	1,61 €
GPB19-M6	19	10	M6	✓	1,72 €
GPB25-M6	25	17	M6	✓	1,90 €
GPB25-M8	25	17	M8	✓	1,90 €
GPB32-M8	32	20	M8	✓	2,11 €
GPB32-M10	32	20	M10	✓	2,11 €
GPB32-M12	32	20	M12	✓	2,11 €
GPB41-M10	41	20	M10	✓	2,80 €
GPB41-M12	41	20	M12	✓	2,80 €
GPB47-M14	47	23	M14	✓	3,76 €
<b>Threaded insert</b>					
GPB19-M6/INS	19	9	M6	✓	2,73 €
GPB25-M8/INS	25	15	M8	✓	2,87 €
GPB32-M8/INS	32	15	M8	✓	2,94 €
GPB32-M10/INS	32	16	M10	✓	3,27 €
GPB41-M10/INS	41	16	M10	✓	4,31 €
GPB41-M12/INS	41	18	M12	✓	5,02 €

\*Depending on availability - Dimensions in mm

## Our other products



WING  
Manually tightened wing nut, Stainless steel DIN 314/315



G01  
Single universal joint, Normal duty



LRRss  
Latch, Spring loaded latch - stainless steel



PT821  
Drive sprocket for slat top chain, Ranges 821 and 805




FF30  
Offset spur gear reducer, from 21.50 to 83 Nm



GDR880  
Straight track for slat top chain, Ranges 880 and 881



 VQT  
Quarter-turn clamp lock, Plastic or stainless steel button



TCXR  
Automatic chain tensioner, With steel sprocket



PW\_PWG15  
Worm - precision range, Stainless steel



CHM40  
Worm and wheel gear reducer, up to 57 Nm



TSRTC  
Stem support for caster, For swivel caster with central



EKN  
Bellows coupling Gerwah®, from 0.5 to 12Nm

## Complementary products



GPB  
Threaded spherical knob, With brass insert



PCH  
Knob for gripping, Mushroom



VTLM  
3 lobed handle, Polyamide - Steel