


Threaded spherical knob



GPB

Technopolymer

- Spherical knob with moulded thread or brass insert
- Small central groove
- Material :
Black Duroplast with brass insert

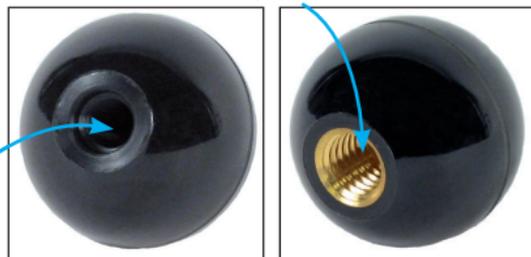


Option

- Stainless steel or polyamide coloured insert (min quantity applies)

Info.

- Not sold individually, please contact us for details

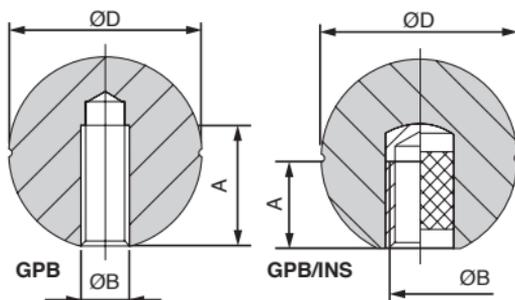

DISCOUNTS

| | | | | | | |
|-------|------|-----|------|------|------|------------|
| Qty | 1+ | 10+ | 20+ | 50+ | 100+ | 200+ |
| Disc. | List | -5% | -10% | -15% | -20% | On request |

| Part number | ØD | A | ØB | Stock* | Price each 1 to 9 |
|------------------------|----|----|-----|--------|-------------------|
| Moulded thread | | | | | |
| GPB19-M4 | 19 | 10 | M4 | ✓ | 2,04 € |
| GPB19-M5 | 19 | 10 | M5 | ✓ | 2,04 € |
| GPB19-M6 | 19 | 10 | M6 | ✓ | 2,04 € |
| GPB25-M6 | 25 | 17 | M6 | ✓ | 2,25 € |
| GPB25-M8 | 25 | 17 | M8 | ✓ | 2,25 € |
| GPB32-M8 | 32 | 20 | M8 | ✓ | 2,53 € |
| GPB32-M10 | 32 | 20 | M10 | ✓ | 2,53 € |
| GPB32-M12 | 32 | 20 | M12 | ✓ | 2,53 € |
| GPB41-M10 | 41 | 20 | M10 | ✓ | 3,35 € |
| GPB41-M12 | 41 | 20 | M12 | ✓ | 3,35 € |
| GPB47-M14 | 47 | 23 | M14 | ✓ | 4,49 € |
| Threaded insert | | | | | |
| GPB19-M6/INS | 19 | 9 | M6 | ✓ | 3,27 € |
| GPB25-M8/INS | 25 | 15 | M8 | ✓ | 3,43 € |
| GPB32-M8/INS | 32 | 15 | M8 | ✓ | 3,51 € |
| GPB32-M10/INS | 32 | 16 | M10 | ✓ | 3,90 € |
| GPB41-M10/INS | 41 | 16 | M10 | ✓ | 5,18 € |
| GPB41-M12/INS | 41 | 18 | M12 | ✓ | 6,04 € |

*Depending on availability - Dimensions in mm

Threaded spherical knob, with fixing moulded thread

Stainless steel 304 or aluminium

GPBss
GPBAL

- **Operating element**
- **Material:**
Inox 304
Aluminium
- **Finishing:** polished

Advantages


- Does not retain dirt or dust



stainless
steel



aluminium

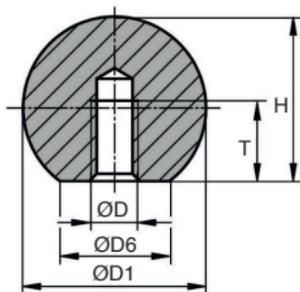

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 20+ |
|-------|-------|-----|------|------------|
| Disc. | Price | -5% | -10% | On request |

| Part number | ØD | ØD1 | ØD6 | H | T | Price per unit 1 to 5 |
|----------------------------|-----|-----|-----|------|------|-----------------------|
| 304 Stainless steel | | | | | | |
| GPB16-M4/SS | M4 | 16 | 8 | 15,0 | 7,2 | 8,98 € |
| GPB20-M5/SS | M5 | 20 | 12 | 18,0 | 9,1 | 9,95 € |
| GPB25-M6/SS | M6 | 25 | 15 | 22,5 | 11,0 | 14,55 € |
| GPB32-M8/SS | M8 | 32 | 18 | 29,0 | 14,5 | 21,64 € |
| GPB40-M10/SS | M10 | 40 | 22 | 37,0 | 18,0 | 38,40 € |
| GPB50-M12/SS | M12 | 50 | 28 | 46,0 | 21,0 | 60,12 € |
| Aluminium | | | | | | |
| GPB16-M4/AL | M4 | 16 | 8 | 15,0 | 7,2 | 6,35 € |
| GPB20-M5/AL | M5 | 20 | 12 | 18,0 | 9,1 | 6,55 € |
| GPB25-M6/AL | M6 | 25 | 15 | 22,5 | 11,0 | 9,17 € |
| GPB32-M8/AL | M8 | 32 | 18 | 29,0 | 14,5 | 13,19 € |
| GPB40-M10/AL | M10 | 40 | 22 | 37,0 | 18,0 | 18,96 € |
| GPB50-M12/AL | M12 | 50 | 28 | 46,0 | 21,0 | 27,51 € |

Dimensions in mm