

Threaded spherical knob



GPB

Technopolymer

- Spherical knob with moulded thread or brass insert
- Small central groove
- Material :
Black Duroplast with brass insert

Option



- Stainless steel or polyamide colored insert on quantities

Info.

- Not sold individually, please contact us for details

Moulded thread

Brass insert

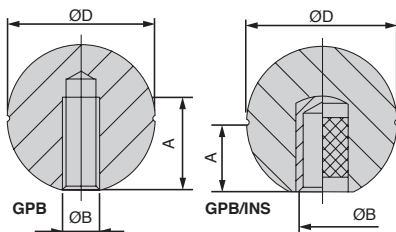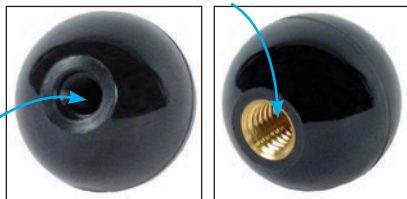

DISCOUNTS

Qty	1+	10+	20+	50+	100+	200+
Disc.	List	-5%	-10%	-15%	-20%	On request

Part number	ØD	A	ØB	Stock*	Price each 1 to 9
Moulded thread					
GPB19-M4	19	10	M4	✓	1,61 €
GPB19-M5	19	10	M5	✓	1,61 €
GPB19-M6	19	10	M6	✓	1,72 €
GPB25-M6	25	17	M6	✓	1,90 €
GPB25-M8	25	17	M8	✓	1,90 €
GPB32-M8	32	20	M8	✓	2,11 €
GPB32-M10	32	20	M10	✓	2,11 €
GPB32-M12	32	20	M12	✓	2,11 €
GPB41-M10	41	20	M10	✓	2,80 €
GPB41-M12	41	20	M12	✓	2,80 €
GPB47-M14	47	23	M14	✓	3,76 €
Threaded insert					
GPB19-M6/INS	19	9	M6	✓	2,73 €
GPB25-M8/INS	25	15	M8	✓	2,87 €
GPB32-M8/INS	32	15	M8	✓	2,94 €
GPB32-M10/INS	32	16	M10	✓	3,27 €
GPB41-M10/INS	41	16	M10	✓	4,31 €
GPB41-M12/INS	41	18	M12	✓	5,02 €

*Depending on availability - Dimensions in mm

Our other products



AC

Strike for toggle latch,
15mm



CCL

Standard wire
thimble, Steel



SCE

U-shaped cable
clamp, Steel



DOMI30

Accessories, Fixing kit



 
PRF_GAL

Roller for aluminium
profile, Fixing kit for
roller concentric



CHT

Asynchronous AC
Motor 1.1 to 1.85kW,
1.1 to 1.85kW



Q3

Double row angular
contact ball bearing,
Angular contact -
Steel



GG1

Ground spur gear,
Heat treated steel



RCC_RCX

Spherical tilt washer -
DIN6319, convex



EPRC

High helix leadscrew,
Cylindrical nut - up to



MDB_MTB

Moulded plastic bevel
gear (nylon), 3:1



BL15

Right angled gearbox,
from 1.10 to 6 Nm

Complementary products



GPB

Threaded spherical
knob, With brass
insert



PCH

Knob for gripping,
Mushroom



VTLM

3 lobed handle,
Polyamide - Steel