

Threaded spherical knob, with fixing moulded thread

GPBSS Stainless steel 304 or aluminium
GPBAL


- **Operating element**
- **Material:**
 Inox 304
 Aluminium
- **Finishing:** polished

Advantages

- Does not retain dirt or dust



stainless steel aluminium

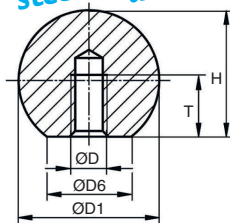

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	Price	-5%	-10%	On request

Part N°	ØD	ØD1	ØD6	H	T	Price per unit
						1 to 4
304 Stainless steel						
GPB16-M4/SS	M4	16	8	15.0	7.2	7,89 €
GPB20-M5/SS	M5	20	12	18.0	9.1	8,72 €
GPB25-M6/SS	M6	25	15	22.5	11.0	12,79 €
GPB32-M8/SS	M8	32	18	29.0	14.5	19,03 €
GPB40-M10/SS	M10	40	22	37.0	18.0	33,75 €
GPB50-M12/SS	M12	50	28	46.0	21.0	52,81 €
Aluminium						
GPB16-M4/AL	M4	16	8	15.0	7.2	5,59 €
GPB20-M5/AL	M5	20	12	18.0	9.1	5,75 €
GPB25-M6/AL	M6	25	15	22.5	11.0	8,04 €
GPB32-M8/AL	M8	32	18	29.0	14.5	11,59 €
GPB40-M10/AL	M10	40	22	37.0	18.0	16,67 €
GPB50-M12/AL	M12	50	28	46.0	21.0	24,17 €

 
Dimensions in mm

Our other products



SLBE

Indexing plunger -
Spacer, Spacer for
SLB and SLBS index
bolts



CF

Cam follower,
Standard - steel




IN2

Internal gear, Steel
20NCD2



SH4

 Parallel axis helical
gear, Steel 20NCD2



M1

Worm and wheel set,
Bronze



 
D19 D29

Compression springs
in metre length
stainless steel, by the
metre



BLM

Spring loaded plunger
with ball tip, Plastic
body



TPR

High helix leadscrew,
Leadscrew only - up
to 40mm per rotation



SA_SAKH

Housing for linear
bearing, Closed - light
load



SHW

Plain washer, A2
Stainless steel



CHTRP

Single and dual
output gearboxes, Up
to 28,8 Nm



AT5M AT10M

AT type timing belt
per metre, AT5 Steel
cored polyurethane

Complementary products



GPBSS

Threaded spherical
knob, Aluminium



GPB

Threaded spherical
knob, Moulded thread



GPB

Threaded spherical
knob, With brass
insert