


Threaded spherical knob, with fixing moulded thread

GPBSS Stainless steel 304 or aluminium
GPBAL

- **Operating element**
- **Material:**
 - Inox 304
 - Aluminium
- **Finishing:** polished

Advantages

- Does not retain dirt or dust

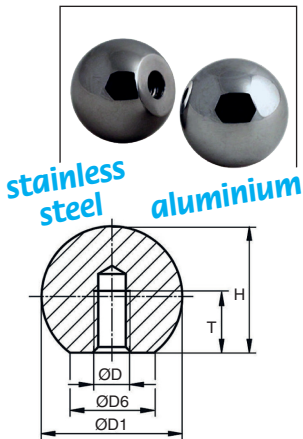

DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	Price	-5%	-10%	On request

Part N°	ØD	ØD1	ØD6	H	T	Price per unit
						1 to 4
304 Stainless steel						
GPB16-M4/SS	M4	16	8	15.0	7.2	7,89 €
GPB20-M5/SS	M5	20	12	18.0	9.1	8,72 €
GPB25-M6/SS	M6	25	15	22.5	11.0	12,79 €
GPB32-M8/SS	M8	32	18	29.0	14.5	19,03 €
GPB40-M10/SS	M10	40	22	37.0	18.0	33,75 €
GPB50-M12/SS	M12	50	28	46.0	21.0	52,81 €
Aluminium						
GPB16-M4/AL	M4	16	8	15.0	7.2	5,59 €
GPB20-M5/AL	M5	20	12	18.0	9.1	5,75 €
GPB25-M6/AL	M6	25	15	22.5	11.0	8,04 €
GPB32-M8/AL	M8	32	18	29.0	14.5	11,59 €
GPB40-M10/AL	M10	40	22	37.0	18.0	16,67 €
GPB50-M12/AL	M12	50	28	46.0	21.0	24,17 €

Dimensions in mm


HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products

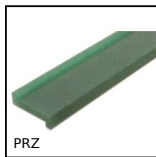

PRZ

Wear strip for slat top chain, Z profile to be filled



KH

Linear bearing, Light



CDGamme

Compression spring
DIN2095, DIN 2095



DSF

Slip friction clutch, 4
to 2600 Nm



ACLERP

Roller block for
aluminium profile,
Without guide rail




CLB_M

Die cast zinc clamping
lever - female, Zamak



BABreglable

Adjustable ball pin
hardened stainless
steel, adjustable

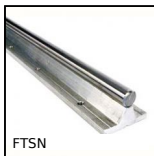

FTSN

Supported shaft for
linear guide, Steel
shaft / Aluminium
support



DGSA

Male rod ends , Steel /
steel - Economy range



AXTR

Axle for tensioner
pulley, Shaft



BIMSS

Indexing plunger mini,
miniature - Stainless
steel



HTD3M_09

HTD Heavy duty
timing pulley, HTD3
Aluminium

Complementary products



GPBSS

Threaded spherical
knob, Aluminium



GPB

Threaded spherical
knob, Moulded thread



GPB

Threaded spherical
knob, With brass
insert