


Threaded spherical knob, with fixing moulded thread

GPBSS Stainless steel 304 or aluminium
GPBAL

- **Operating element**
- **Material:**
 - Inox 304
 - Aluminium
- **Finishing:** polished

Advantages

- Does not retain dirt or dust

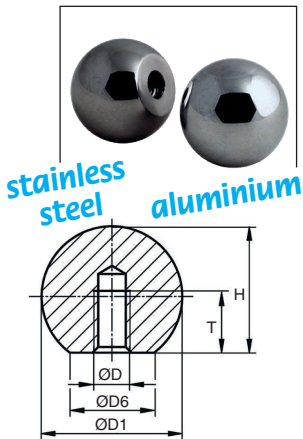


DISCOUNTS

Qty	1+	5+	10+	20+
Disc.	Price	-5%	-10%	On request

Part N°	ØD	ØD1	ØD6	H	T	Price per unit
						1 to 4
304 Stainless steel						
GPB16-M4/SS	M4	16	8	15.0	7.2	7,89 €
GPB20-M5/SS	M5	20	12	18.0	9.1	8,72 €
GPB25-M6/SS	M6	25	15	22.5	11.0	12,79 €
GPB32-M8/SS	M8	32	18	29.0	14.5	19,03 €
GPB40-M10/SS	M10	40	22	37.0	18.0	33,75 €
GPB50-M12/SS	M12	50	28	46.0	21.0	52,81 €
Aluminium						
GPB16-M4/AL	M4	16	8	15.0	7.2	5,59 €
GPB20-M5/AL	M5	20	12	18.0	9.1	5,75 €
GPB25-M6/AL	M6	25	15	22.5	11.0	8,04 €
GPB32-M8/AL	M8	32	18	29.0	14.5	11,59 €
GPB40-M10/AL	M10	40	22	37.0	18.0	16,67 €
GPB50-M12/AL	M12	50	28	46.0	21.0	24,17 €

Dimensions in mm

 
Our other products



PRF45 GOU
Chute profile,
Accessories



 SSB
Stainless steel bevel
gear, 1:1



MAT
Drawn ground round
bar, 100C6 steel bar



CSS
Spherical bushing,
Steel / self lubricating
steel



PSG2
Spur gear - precision
range, Case hardened
steel 20NCD2



SSB
Stainless steel bevel
gear, 1:1



CHA_GC_9SS
Stainless steel garnet
hinge, To be welded



PSG08S
Spur gear - precision
range, Stainless steel
316



LVT
Miniature motorised
actuator 4A, 4 amperes



GG1
Ground spur gear,
Heat treated steel



AFSE
Locking pin with
interlocking safety



UGH40
H Type Guide units,
For Ø40 actuators

Complementary products



GPB5S
Threaded spherical
knob, Aluminium



GPB
Threaded spherical
knob, Moulded thread



GPB
Threaded spherical
knob, With brass
insert