




- Hand brushes are used for manual cleaning, scouring, dust removal, stripping, descaling, honing or deburring operations on cylindrical surfaces: inside tubes, bottles, pin holes, rivet holes, tapped holes, secant holes, etc.
- These brushes can be used in a wide range of industries: mechanical (machine tools, maintenance), food processing, pharmaceutical and medical.

In practice

- Scrub the walls of the element to be cleaned using a rotating and back-and-forth motion.

Advice

- To prevent the bristles of the brush from twisting, we recommend that you choose one that the diameter is 10 to 15% larger than the diameter of the hole you wish to clean.

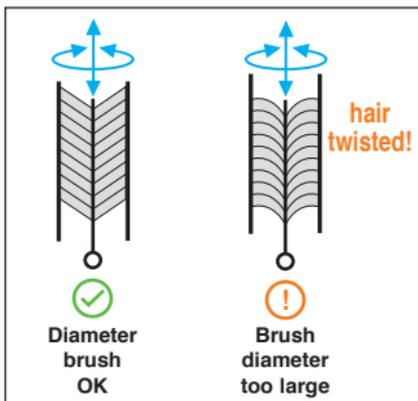

It's the end of the brush that works, not the edge.
It needs room to stand up straight


Deburring and stripping stainless steel

GPLSS
- Stainless steel deburring brushes
- Materials:

- Twisted galvanised steel
- Stainless steel covering

Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

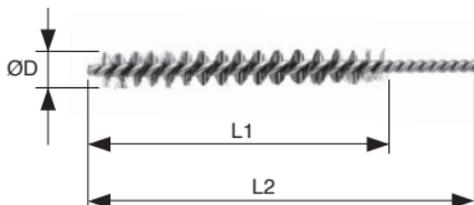
Deburring a gear bore

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List		-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Overall length L2	Stock*	Price each 1 to 9
GPL5-100/SS	5	100	300	✓	12,23 €
GPL8-100/SS	8	100	300	✓	10,46 €
GPL10-100/SS	10	100	300	✓	9,55 €
GPL12-100/SS	12	100	300	✓	9,55 €
GPL15-100/SS	15	100	300	✓	9,67 €
GPL20-100/SS	20	100	300	✓	10,70 €
GPL25-100/SS	25	100	300	✓	10,11 €

*Depending on availability - Dimensions in mm

- Deburring and cleaning brush for all materials

- Materials:

Twisted galvanised steel


Galvanized steel twist

Steel covering



Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

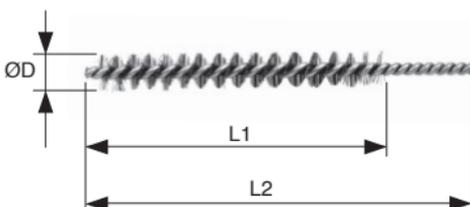

Stripping of a pulley bore

DISCOUNTS

Qty	1+	10+	25+	50+
Disc. List	-5%	-10%	On request	

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/AC	5	100	300	✓	12,42 €
GPL8-100/AC	8	100	300	-	8,07 €
GPL10-100/AC	10	100	300	✓	8,07 €
GPL12-100/AC	12	100	300	-	8,22 €
GPL15-100/AC	15	100	300	-	8,53 €
GPL20-100/AC	20	100	300	-	10,08 €
GPL25-100/AC	25	100	300	-	10,08 €

*Depending on availability - Dimensions in mm

For deburring and stripping softer materials

GPL_{BR}


- Deburring and stripping brushes for aluminium, bronze and brass

- Materials:

- Twisted galvanised steel
- Brass covering

Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

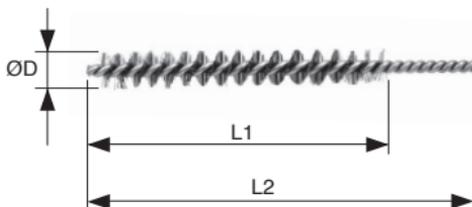

Deburring a trapezoidal nut

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request


Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/BR	5	100	300	✓	12,23 €
GPL8-100/BR	8	100	300	-	10,24 €
GPL10-100/BR	10	100	300	-	9,22 €
GPL12-100/BR	12	100	300	✓	9,28 €
GPL15-100/BR	15	100	300	✓	9,28 €
GPL20-100/BR	20	100	300	✓	9,84 €
GPL25-100/BR	25	100	300	✓	9,84 €

*Depending on availability - Dimensions in mm

- Deburring brushes for soft materials



- Materials:

- Twisted galvanised steel
- Nylon covered

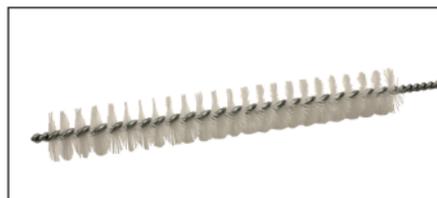

Applications

- Gentle cleaning of hollow containers (tubes, bottles, holes)
- Gentle cleaning of hard-to-reach areas

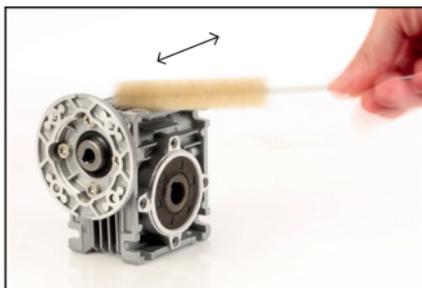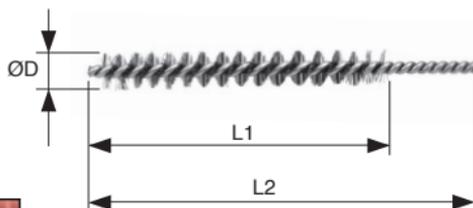

Cleaning the cooling fins of a gearbox

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL4-100/NY	4	100	300	✓	7,76 €
GPL6-100/NY	6	100	300	✓	5,11 €
GPL8-100/NY	8	100	300	✓	5,14 €
GPL10-100/NY	10	100	300	✓	5,18 €
GPL12-100/NY	12	100	300	✓	5,21 €
GPL15-100/NY	15	100	300	✓	5,27 €
GPL20-100/NY	20	100	300	✓	5,32 €
GPL25-100/NY	25	100	300	✓	5,41 €
GPL30-100/NY	30	100	300	✓	5,59 €
GPL40-100/NY	40	100	300	✓	5,79 €

*Depending on availability - Dimensions in mm

- Brushes for the cleaning and removal of dust

- Materials:




Twisted galvanised steel
Hog bristle silk covering

Application

- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas

Advantage

- Anti-static

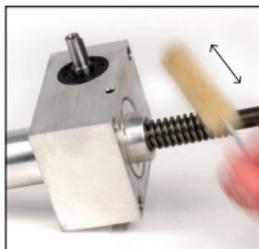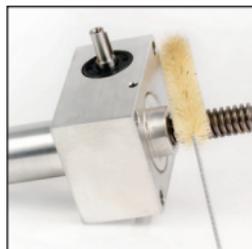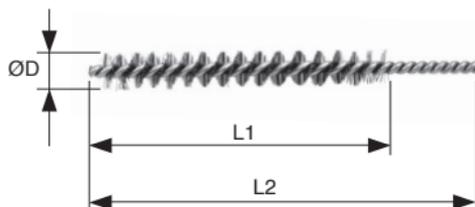

Cleaning of hard-to-reach areas

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL15-100/SO	15	80	300	✓	8,53 €
GPL20-100/SO	20	80	300	-	10,08 €
GPL25-100/SO	25	80	300	✓	8,99 €

*Depending on availability - Dimensions in mm

Our other products



BCA

Steel splined collar,
Steel



PCS6ECO

Chain sprocket - steel,
6mm (DIN 04-1)



BPHR

Ball transfer unit
housed spring loaded,
High



TCLar

Automatic chain
tensioner, With wide
guide



SBF

Sealed flange bearing
unit for Food Industry,
cover



AC

Strike for toggle latch,
15mm



DOMI50

Domino 50 adjustable
slide, Slide DOMILINE
50 with counter and handw...



CHMX_CHMDX

Shaft for worm and
wheel reducer CHMR
and CHM, CHMR and
CHM gearbox...



SHA_PTR

Handwheel with
folding handle,



HCSS

Set screw with
hexagonal socket,



PCLA_T


Technopolymer
clamping lever - male,



SCA

Flat cable clamp,
Steel

Complementary products

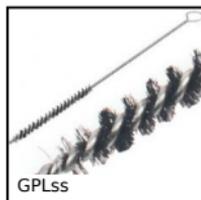


GPLss

Brush, stainless steel




GPLbr

Brush, brass

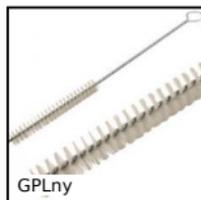

GPLny

Brush, nylon

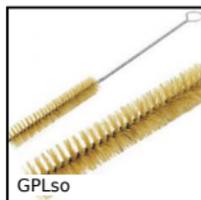

GPLso

Brush, silk