

Steel brush

GPLAC

For deburring and stripping

- Deburring and cleaning brush for all materials

- Materials:

Twisted galvanised steel


Galvanized steel twist

Steel covering



Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

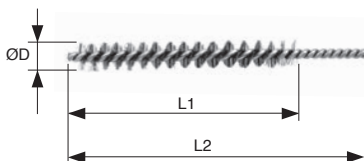

Stripping of a pulley bore

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/AC	5	100	300	✓	10,19 €
GPL8-100/AC	8	100	300	-	6,62 €
GPL10-100/AC	10	100	300	✓	6,62 €
GPL12-100/AC	12	100	300	-	6,75 €
GPL15-100/AC	15	100	300	-	7,00 €
GPL20-100/AC	20	100	300	-	8,27 €
GPL25-100/AC	25	100	300	-	8,27 €

Dimensions in mm

Our other products



CHML40

Worm and wheel gear reducer, up to 57 Nm
- Integrated torque limiter




H4

Crossed helical gear
crossed axis at 90°,
Steel 20NCD2




SHNbr

Hexagonal nut
DIN934, Brass

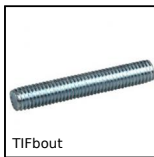

TIFbout

 Threaded stud -
DIN976A, Steel



T5courroie

T type timing belt, T5
Steel cored
polyurethane



VDSQCB

Sliding lock
adjustment system,
Blocking wedge



ACLCHARJ

Hinge for aluminium
profile, Adjusts in 2
directions



BMF

Knurled knob -
female, Knurled -
blind




PITA

Locking bolt, with T
handle



NK17

 Drylin® miniature
guiding system, Width
17 mm



M0


Worm and wheel set,
Machined plastic
(delrin)



SVR30

Screwjack with
travelling nut, with
moving nut

 Complementary products




GPLss

Brush, stainless steel




GPLbr

 Brush, brass



GPLny

Brush, nylon

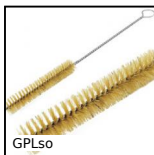

GPLso

Brush, silk