

# Steel brush

GPLAC

For deburring and stripping

## - Deburring and cleaning brush for all materials

### - Materials:

Twisted galvanised steel


Galvanized steel twist

Steel covering



## Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

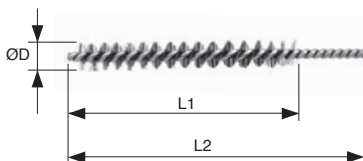

Stripping of a pulley bore

## DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/AC	5	100	300	✓	10,19 €
GPL8-100/AC	8	100	300	-	6,62 €
GPL10-100/AC	10	100	300	✓	6,62 €
GPL12-100/AC	12	100	300	-	6,75 €
GPL15-100/AC	15	100	300	-	7,00 €
GPL20-100/AC	20	100	300	-	8,27 €
GPL25-100/AC	25	100	300	-	8,27 €

Dimensions in mm

## Our other products



BSCf  
Knurled torque knobs  
- female, Knurled  
threaded torque



BPPE  
Ball transfer unit push  
fit, Light



GBS  
Nut for ballscrew,  
Flanged ballscrew nut



M1  
Worm and wheel set,  
Hardened steel



S20  
Short housing for  
open linear bearing,  
Opened - slim



BH01  
Single housed  
bearing, Bearing fitted  
with adhesive



PR40  
Articulated foot Ø50,  
Ø 50



EHD12  
Internal epicyclic  
servo reducers, from  
60 to 140 Nm



E20  
Right angle helical  
reducers, from 0.60 to  
1.20 Nm



PRF\_JL6  
Lip seal for panel,  
Door seal - Ø 6mm

 


CHTRP  
Single and dual  
output gearboxes, Up  
to 1.20 Nm



KITbuh  
24V DC motorisation  
kit, Planetary gears


## Complementary products




GPLss  
Brush, stainless steel



 GPLbr  
Brush, brass



GPLny  
Brush, nylon

 

GPLso  
Brush, silk