

# Steel brush

GPLAC

For deburring and stripping

## - Deburring and cleaning brush for all materials

### - Materials:

Twisted galvanised steel


Galvanized steel twist

Steel covering



## Applications

- Deburring of pin holes, rivet holes, tapped holes, intersecting holes
- Cleaning of hollow containers (tubes, bottles, holes)
- Cleaning of hard-to-reach areas
- Removing rust
- Cleaning
- Stripping

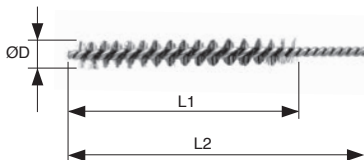

Stripping of a pulley bore

## DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	Brush diameter ØD	Brush length L1	Total length L2	Stock*	Price each 1 to 9
GPL5-100/AC	5	100	300	✓	10,19 €
GPL8-100/AC	8	100	300	-	6,62 €
GPL10-100/AC	10	100	300	✓	6,62 €
GPL12-100/AC	12	100	300	-	6,75 €
GPL15-100/AC	15	100	300	-	7,00 €
GPL20-100/AC	20	100	300	-	8,27 €
GPL25-100/AC	25	100	300	-	8,27 €

Dimensions in mm

## Our other products



PM2

Worm and wheel set,  
Bronze



CLG3

Moulded plastic spur  
gear, Moulded plastic  
(nylon)



PAV

Fixed anti-vibration  
foot mount, Vibration-  
dampening



LVT

Miniature motorised  
actuator 1A, 1 amper



DOG258

Motor-gearbox 12V  
and 24V DC, from 12  
to 15 Nm



VRSF

Male swivelling lifting  
ring, Male swivelling



MSP19

Masterplate®  
glueable insert  
Ø19/Ø20, Cylindrical  
with nut



MEB

Moulded plastic bevel  
gear (nylon), 1:1



CHAR7520

Spring hinge, screwed



PR40

Articulated foot Ø40,  
Ø 40



PW\_PWG15

 
Worm - precision  
range, Steel



TUBE25\_25

Square Tube,  
Aluminium or  
Stainless steel

## Complementary products




GPLss

Brush, stainless steel




GPLbr

Brush, brass

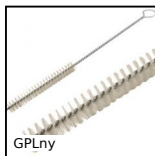

GPLny

Brush, nylon

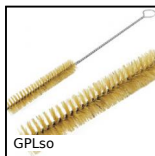

GPLso

Brush, silk